

**IE-PH-V01M-BP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connectors according to IEC  
61076-3-106 ver.1 (Ethernet/IP), metal, empty housing

**General ordering data**

Version	Empty enclosure, Plug housing, bending protection, Variant 1 to IEC 61076-3-106, IP67
Order No.	<a href="#">1962560000</a>
Type	IE-PH-V01M-BP
GTIN (EAN)	4032248644698
Qty.	10 pc(s).

## IE-PH-V01M-BP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	126 mm	Depth (inches)	4.961 inch
Height	30 mm	Height (inches)	1.181 inch
Width	30 mm	Width (inches)	1.181 inch
Net weight	128.24 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Plugging cycles	750	Protection degree	IP67

## General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

## Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

## Approvals

ROHS	Conform
------	---------

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">DUXR.E316369</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

### IE-PH-V01M-BP

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26


D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Dimensioned drawing

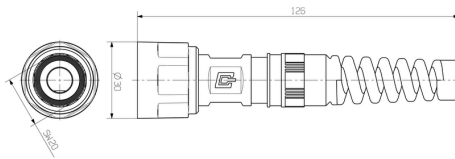

## IE-PH-V01M-BP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Dust caps



For protecting your devices against dust and dirt.

## General ordering data

Type	IE-PP-V01P	Version
Order No.	<a href="#">1965690000</a>	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 pc(s).	

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

## IE-PH-V01M-BP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## RJ45



RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,  
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

## General ordering data

Type	IE-PI-RJ45-FH	Version
Order No.	<a href="#">1962730000</a>	Plug insert RJ45 IDC, Plug insert RJ45, no tools required, TIA-568A,
GTIN (EAN)	4032248654017	EIA/TIA T568 B, PROFINET
Qty.	10 pc(s).	
Type	IE-PI-RJ45-TH	Version
Order No.	<a href="#">1962720000</a>	Plug insert RJ45 IDC, Plug insert RJ45, crimp
GTIN (EAN)	4032248644834	
Qty.	10 pc(s).	

## LWL-LC



FO LC inserts for plug-in connectors ver.1 / 4 / 14

## General ordering data

Type	IE-PI-2LC-MM	Version
Order No.	<a href="#">1962780000</a>	LC insert, Plug insert 2 LC, multimode
GTIN (EAN)	4032248644865	
Qty.	10 pc(s).	
Type	IE-PI-2LC-SM	Version
Order No.	<a href="#">1962790000</a>	LC insert, Plug insert 2 LC, singlemode
GTIN (EAN)	4032248644872	
Qty.	10 pc(s).	

## IE-PH-V01M-BP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## LWL-SC

FO SC inserts for plug-in connectors ver. 1 / 4 / 14



## General ordering data

Type	IE-PI-SCRJ-POF	Version
Order No.	<a href="#">1067410000</a>	SC insert, Plug SCRJ, POF
GTIN (EAN)	4032248820870	
Qty.	10 pc(s).	
Type	IE-PI-2SC-MM	Version
Order No.	<a href="#">1962750000</a>	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644841	
Qty.	10 pc(s).	
Type	IE-PI-SCRJ-SM	Version
Order No.	<a href="#">1067390000</a>	SC insert, Plug SCRJ, singlemode
GTIN (EAN)	4032248820863	
Qty.	10 pc(s).	
Type	IE-PI-2SC-SM	Version
Order No.	<a href="#">1962760000</a>	SC insert, Plug insert 2 SC, singlemode
GTIN (EAN)	4032248654000	
Qty.	10 pc(s).	
Type	IE-PI-2SC-POF	Version
Order No.	<a href="#">1962770000</a>	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644858	
Qty.	10 pc(s).	

## Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14



## General ordering data

Type	IE-PIC-HYB-S-O,5-300	Version
Order No.	<a href="#">1096180000</a>	Crimp contact, for plug insert, Hybrid
GTIN (EAN)	4032248869152	
Qty.	300 pc(s).	

## IE-PH-V01M-BP

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

Type	IE-PI-HYB-10P	Version
Order No.	<a href="#">1068990000</a>	Insert, for plug insert, Hybrid
GTIN (EAN)	4032248823963	
Qty.	1 pc(s).	