

IE-PH-V01M-BP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connectors according to IEC
61076-3-106 ver. 1 (Ethernet/IP), metal, empty housing

General ordering data

Version	Empty enclosure, Plug housing, bending protection, Variant 1 to IEC 61076-3-106, IP67
Order No.	1962560000
Type	IE-PH-V01M-BP
GTIN (EAN)	4032248644698
Qty.	10 pc(s).

IE-PH-V01M-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	126 mm	Depth (inches)	4.961 inch
Height	30 mm	Height (inches)	1.181 inch
Width	30 mm	Width (inches)	1.181 inch
Net weight	128.24 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Plugging cycles	750	Protection degree	IP67

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	GOST Approval DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN

IE-PH-V01M-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Dimensioned drawing

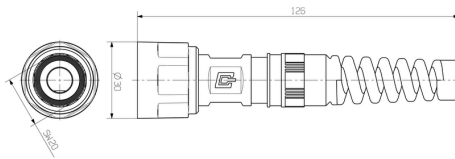

IE-PH-V01M-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14



General ordering data

Type	IE-PI-HYB-10P	Version
Order No.	1068990000	Insert, for plug insert, Hybrid
GTIN (EAN)	4032248823963	
Qty.	1 pc(s).	
Type	IE-PIC-HYB-S-0,5-300	Version
Order No.	1096180000	Crimp contact, for plug insert, Hybrid
GTIN (EAN)	4032248869152	
Qty.	300 pc(s).	

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

IE-PH-V01M-BP**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****LWL-LC**

FO LC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-PI-2LC-MM	Version
Order No.	1962780000	LC insert, Plug insert 2 LC, multimode
GTIN (EAN)	4032248644865	
Qty.	10 pc(s).	
Type	IE-PI-2LC-SM	Version
Order No.	1962790000	LC insert, Plug insert 2 LC, singlemode
GTIN (EAN)	4032248644872	
Qty.	10 pc(s).	

Dust caps

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-PP-V01P	Version
Order No.	1965690000	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 pc(s).	

IE-PH-V01M-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

RJ45

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...



General ordering data

Type	IE-PI-RJ45-FH	Version
Order No.	1962730000	Plug insert RJ45 IDC, Plug insert RJ45, no tools required, TIA-568A,
GTIN (EAN)	4032248654017	EIA/TIA T568 B, PROFINET
Qty.	10 pc(s).	
Type	IE-PI-RJ45-TH	Version
Order No.	1962720000	Plug insert RJ45 IDC, Plug insert RJ45, crimp
GTIN (EAN)	4032248644834	
Qty.	10 pc(s).	

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14



General ordering data

Type	IE-PI-2SC-SM	Version
Order No.	1962760000	SC insert, Plug insert 2 SC, singlemode
GTIN (EAN)	4032248654000	
Qty.	10 pc(s).	
Type	IE-PI-SCRJ-POF	Version
Order No.	1067410000	SC insert, Plug SCRJ, POF
GTIN (EAN)	4032248820870	
Qty.	10 pc(s).	
Type	IE-PI-SCRJ-SM	Version
Order No.	1067390000	SC insert, Plug SCRJ, singlemode
GTIN (EAN)	4032248820863	
Qty.	10 pc(s).	
Type	IE-PI-2SC-POF	Version
Order No.	1962770000	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644858	
Qty.	10 pc(s).	

IE-PH-V01M-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	IE-PI-2SC-MM	Version
Order No.	1962750000	SC insert, Plug insert 2 SC, multimode
GTIN (EAN)	4032248644841	
Qty.	10 pc(s).	