

**IE-PS-V05M-RJ45-TH****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

HDC plug-in connector set according to IEC 61076-3-106  
ver.5 in metal, with RJ45 insert

**General ordering data**

Version	RJ45 crimp plug, Variant 5, Cat.6 <sub>A</sub> / Class E <sub>A</sub> (ISO/IEC 11801 2010)
Order No.	<a href="#">1963110000</a>
Type	IE-PS-V05M-RJ45-TH
GTIN (EAN)	4032248651610
Qty.	10 pc(s).

## IE-PS-V05M-RJ45-TH

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Net weight	83.28 g
------------	---------

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## General data

Connection 1	RJ45	Connection 2	Crimp
Description of article	Variant 5	Housing main material	diecast aluminium
Insulation cross-section, min.	0.85 mm	Insulation cross-section, max.	1.05 mm
Category	Cat.6A / Class EA (ISO/IEC 11801 2010)	Contact surface	Gold over nickel
Connection diameter, solid	0.36...0.51 mm	Conductor connection cross-section, solid (AWG)	AWG 26/1...AWG 24/1
Connection diameter, flexible	0.46...0.61 mm	Conductor connection cross-section, flexible (AWG)	AWG 27/7...AWG 24/7
MICE classification M	M <sub>3</sub>	MICE classification I	I <sub>3</sub>
MICE classification C	C <sub>1</sub>	MICE classification E	E <sub>3</sub>
Sheath diameter, min.	5 mm	Sheath diameter, max.	12 mm
Shielding	360°; all-round enclosure	Protection degree	IP67
Plugging cycles	750		

## Electrical properties

Dielectric strength, contact / contact	≥ 1000 V AC/DC	Dielectric strength, contact / shield	≥ 1500 V AC/DC
----------------------------------------	----------------	---------------------------------------	----------------

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 5, IEC 60603-7-51
-------------------------	---------	--------------------	----------------------------------------

## Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6b1, 6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

**IE-PS-V05M-RJ45-TH****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

**Downloads**

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 4 connector channel DUXR.E316369</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-PS-V05M-RJ45-TH

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Dimensioned drawing

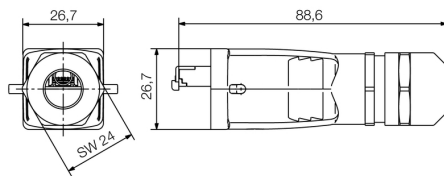

**IE-PS-V05M-RJ45-TH****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-PP-V05M	Version
Order No.	<a href="#">1968920000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248692668	
Qty.	1 pc(s).	