

IE-PS-V01M-RJ45-TH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.
RJ45 insert

General ordering data

Version	RJ45 crimp plug, Variant 1 metal, Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
Order No.	1963140000
Type	IE-PS-V01M-RJ45-TH
GTIN (EAN)	4032248651641
Qty.	1 pc(s).

IE-PS-V01M-RJ45-TH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	10.5 g
------------	--------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	Crimp
Description of article	Variant 1 metal	Housing main material	Zinc diecast
Insulation cross-section, min.	0.85 mm	Insulation cross-section, max.	1.05 mm
Category	Cat.6A / Class E _A (ISO/IEC 11801 2010)	Contact surface	Gold over nickel
Connection diameter, solid	0.36...0.51 mm	Conductor connection cross-section, solid (AWG)	AWG 26/1...AWG 24/1
Connection diameter, flexible	0.46...0.61 mm	Conductor connection cross-section, flexible (AWG)	AWG 27/7...AWG 24/7
MICE classification M	M ₃	MICE classification I	I ₃
MICE classification C	C ₁	MICE classification E	E ₃
Sheath diameter, min.	5 mm	Sheath diameter, max.	10 mm
Shielding	360°; all-round enclosure	Protection degree	IP67
Plugging cycles	750		

Electrical properties

Dielectric strength, contact / contact	≥ 1000 V AC/DC	Dielectric strength, contact / shield	≥ 1500 V AC/DC
----------------------------------------	----------------	---------------------------------------	----------------

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 1, IEC 60603-7-51
-------------------------	---------	--------------------	----------------------------------------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

IE-PS-V01M-RJ45-TH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	GOST Approval ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 4 connector channel DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONCONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN

IE-PS-V01M-RJ45-TH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Dimensioned drawing

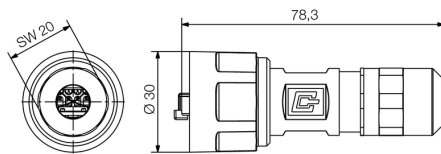

IE-PS-V01M-RJ45-TH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V01P	Version
Order No.	1965690000	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 pc(s).	

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	