

IE-PS-V05M-RJ45-FH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

HDC plug-in connector set according to IEC 61076-3-106
ver.5 in metal, with RJ45 insert

General ordering data

Version	RJ45 plug, no tools required, Variant 5, Cat.6 _A / Class E _A (ISO/IEC 11801 2010)
Order No.	1963200000
Type	IE-PS-V05M-RJ45-FH
GTIN (EAN)	4032248651689
Qty.	10 pc(s).

IE-PS-V05M-RJ45-FH

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	90.873 g
------------	----------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	IDC
Description of article	Variant 5	Colour	black
Housing main material	diecast aluminium	Insulation cross-section, min.	0.85 mm
Insulation cross-section, max.	1.6 mm	Category	Cat. 6 _A / Class E _A (ISO/IEC 11801 2010)
Contact surface	Gold over nickel	Connection diameter, solid	0.4...0.64 mm
Conductor connection cross-section, solid (AWG)	AWG 24...AWG 22	Connection diameter, flexible	0.48...0.76 mm
Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22	MICE classification M	M ₃
MICE classification I	I ₃	MICE classification C	C ₁
MICE classification E	E ₃	Sheath diameter, min.	5 mm
Sheath diameter, max.	12 mm	Shielding	360°; all-round enclosure
Protection degree	IP67	Plugging cycles	750
Ability to reconnect	≥ 10 cycles (for the same or larger cross-section)		

Electrical properties

Dielectric strength, contact / contact	≥ 1000 V AC/DC	Dielectric strength, contact / shield	≥ 1500 V AC/DC
--	----------------	---------------------------------------	----------------

General standards

Application-specific communication cable facilities	PROFINET installation instructions	Certificate no. (cULus)	E316369
Connector standard	IEC 61076-3-106 Var. 5, IEC 60603-7-51		

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6bl, 6c

IE-PS-V05M-RJ45-FH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Downloads

Approval/Certificate/Document of Conformity	GOST Approval ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 4 connector channel DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONCONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN FL FIELDWIRING EN PI PROFINET CABLING EN


IE-PS-V05M-RJ45-FH

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

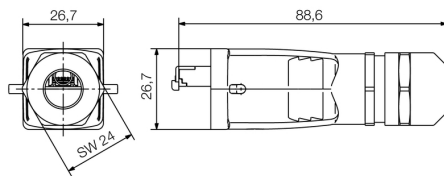

IE-PS-V05M-RJ45-FH**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V05M	Version
Order No.	1968920000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248692668	
Qty.	1 pc(s).	