

IE-PS-V01M-2SC-POF**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.
SC insert

General ordering data

Version	FO connector, Version 1, SC-RJ POF, IP67
Order No.	1963280000
Type	IE-PS-V01M-2SC-POF
GTIN (EAN)	4032248651757
Qty.	10 pc(s).

IE-PS-V01M-2SC-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	87 mm	Depth (inches)	3.425 inch
Height	30 mm	Height (inches)	1.181 inch
Width	30 mm	Width (inches)	1.181 inch
Net weight	125.5 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Connection 1	SCRJ
Connection 2	Rapid connection system: crimping, cutting	Description of article	Version 1, SC-RJ POF
Fibre type	POF	Housing main material	Zinc diecast
Housing material, insert	PA, Zinc diecast	Insertion loss	0.5 dB singlemode, 0.4 dB multimode, ≤ 1.0 dB POF
Plugging cycles	500	Protection degree	IP67
Return loss (attenuation)	40 dB singlemode; 30 dB multimode	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm		

General standards

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-24
--------------------	---

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	GOST Approval
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN

Creation date July 25, 2024 8:21:58 AM CEST

IE-PS-V01M-2SC-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Drawings

Dimensioned drawing

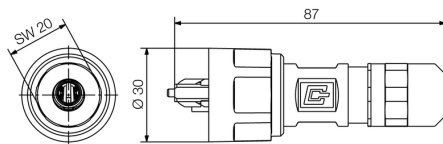

IE-PS-V01M-2SC-POF**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Crimp Sets**

Crimp sets

General ordering data

Type	TOOL SET IE-POF	Version
Order No.	1208930000	Crimping tool: HTX-IE-POF, Stripping tool: Multi-Stripax IE-POF
GTIN (EAN)	4032248990283	
Qty.	1 pc(s).	

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-SCRJ-IP67-POF-100	Version
Order No.	1278430000	FO connector, Replacement crimp barrel, IP67 with housing
GTIN (EAN)	4050118069136	
Qty.	100 pc(s).	

IE-PS-V01M-2SC-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V01P	Version
Order No.	1965690000	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 pc(s).	

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	