

IE-BS-V01M-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.
LC insert

General ordering data

Version	Flange FO, IP67, Version 1, LC Duplex coupling, Singlemode
Order No.	1963430000
Type	IE-BS-V01M-LCD-SM-C
GTIN (EAN)	4032248645527
Qty.	10 pc(s).

IE-BS-V01M-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	33.3 mm	Depth (inches)	1.311 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	60 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Connection 1	LC Duplex
Connection 2		Description of article	Version 1, LC Duplex coupling
	LC Duplex		
Fibre type	Singlemode	Housing main material	Zinc diecast
Insertion loss	≤ 0.5 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 40 dB

General standards

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-20
--------------------	---

Classifications

ETIM 6.0	EC000752	ETIM 7.0	EC000752
ETIM 8.0	EC000752	ETIM 9.0	EC000752
ECLASS 9.1	19-17-01-16	ECLASS 10.0	19-17-01-16
ECLASS 11.0	19-17-01-16	ECLASS 12.0	19-17-01-16
ECLASS 13.0	19-17-01-16		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

Approvals

ROHS	Conform
------	---------

IE-BS-V01M-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Downloads**Approval/Certificate/Document of Con-
formity[GOST Approval](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[Technical change to Bulkhead Variant 1 \(Metal\) - EN](#)[Technical change to Bulkhead Variant 1 \(Metal\) - DE](#)[20190724 Technische Änderung zu Flansch Variante 1 \(Metall\)](#)[20190724 Technische Änderung zu Flansch Variante 1 \(Metall\)](#)[20190724 Technical change to Bulkhead Variant 1 \(Metal\)](#)

User Documentation

[MAN IE GUIDE DE](#)[MAN IE GUIDE EN](#)[Designation key / Type key](#)[Manual](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)[PI PROFINET CABLING EN](#)[PI PROFINET CABLING EN](#)


IE-BS-V01M-LCD-SM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com


Drawings

Installation cut-out

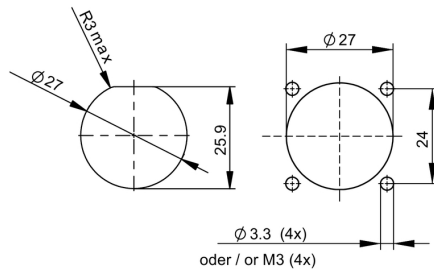

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

Detailed drawing

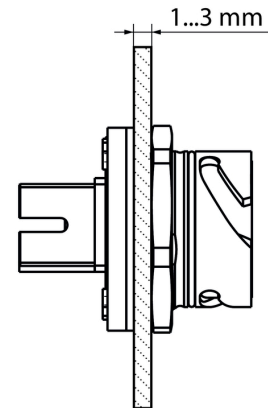

Wall thickness when using the central screw connection

IE-BS-V01M-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version
Order No.	1965700000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	