

IE-BS-V04P-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with LC insert

General ordering data

| | |
|------------|--|
| Version | Flange FO, IP67, Version 4, LC Duplex coupling, Singlemode |
| Order No. | 1963450000 |
| Type | IE-BS-V04P-LCD-SM-C |
| GTIN (EAN) | 4032248645541 |
| Qty. | 10 pc(s). |

IE-BS-V04P-LCD-SM-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|---------|-----------------|------------|
| Depth | 45.3 mm | Depth (inches) | 1.783 inch |
| Height | 38 mm | Height (inches) | 1.496 inch |
| Width | 27 mm | Width (inches) | 1.063 inch |
| Net weight | 26.7 g | | |

Temperatures

| | |
|-----------------------|----------------|
| Operating temperature | -40 °C...70 °C |
|-----------------------|----------------|

General data

| | | | |
|-------------------|---------------|---------------------------|-------------------------------|
| Colour | Miscellaneous | Connection 1 | LC Duplex |
| Connection 2 | | Description of article | Version 4, LC Duplex coupling |
| | LC Duplex | | |
| Fibre type | Singlemode | Housing main material | PA UL 94 V0 |
| Insertion loss | ≤ 0.5 dB | Plugging cycles | 500 |
| Protection degree | IP67 | Return loss (attenuation) | ≥ 40 dB |

General standards

| | |
|--------------------|---|
| Connector standard | IEC 61076-3-106 Var. 4, IEC 61754-20 |
|--------------------|---|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001122 | ETIM 7.0 | EC001122 |
| ETIM 8.0 | EC001122 | ETIM 9.0 | EC001122 |
| ECLASS 9.0 | 19-17-01-22 | ECLASS 9.1 | 19-17-01-22 |
| ECLASS 10.0 | 19-17-01-22 | ECLASS 11.0 | 19-17-01-22 |
| ECLASS 12.0 | 19-17-01-22 | ECLASS 13.0 | 19-17-01-22 |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| REACH SVHC | / |
| RoHS Compliance Status | Compliant without exemption |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

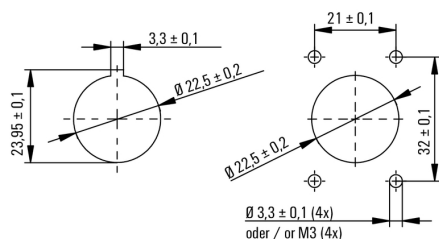
| | |
|---|--|
| Approval/Certificate/Document of Conformity | GOST Approval |
| Engineering Data | CAD data – STEP |
| User Documentation | MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual |
| Catalogues | Catalogues in PDF-format |
| Brochures | FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN |

IE-BS-V04P-LCD-SM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Installation cut-out**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

IE-BS-V04P-LCD-SM-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | IE-BP-V04P | Version |
| Order No. | 1963900000 | Flange-mounted housing, protective cap |
| GTIN (EAN) | 4032248646326 | |
| Qty. | 10 pc(s). | |

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | ESG 9/11 K MC NE WS | Version |
| Order No. | 1857440000 | ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive |
| GTIN (EAN) | 4032248402731 | |
| Qty. | 200 pc(s). | |