

IE-BH-V01M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connectors according to IEC
61076-3-106 ver.1 (Ethernet/IP), metal, empty housing

General ordering data

Version	Empty enclosure, Flange-mounted housing, Variant 1 to IEC 61076-3-106, IP67
Order No.	1963540000
Type	IE-BH-V01M
GTIN (EAN)	4032248645633
Qty.	10 pc(s).

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	23.5 mm	Depth (inches)	0.925 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	46.6 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Plugging cycles	750	Protection degree	IP67
Type of mounting	4 screws, Central nut		

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	GOST Approval DUXR.E316369
Engineering Data	CAD data – STEP
Product Change Notification	Technical change to Bulkhead Variant 1 (Metal) - EN Technical change to Bulkhead Variant 1 (Metal) - DE 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technical change to Bulkhead Variant 1 (Metal)
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-BH-V01M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Installation cut-out

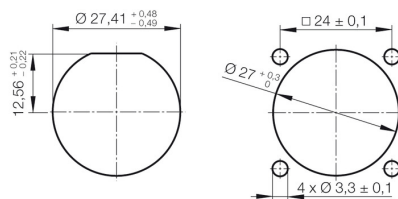

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14



General ordering data

Type	IE-BI-SCRJ2SC-SM-C	Version
Order No.	1962870000	SC insert, Bulkhead insert SCRJ to 2 SC, singlemode
GTIN (EAN)	4032248645060	
Qty.	10 pc(s).	
Type	IE-BI-SCRJ2SC-MM-C	Version
Order No.	1964430000	SC insert, Bulkhead insert SCRJ to 2 SC, multimode
GTIN (EAN)	4032248649044	
Qty.	10 pc(s).	

USB



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-USB-A	Version
Order No.	1019570000	USB insert, Flange insert, type A
GTIN (EAN)	4032248731602	
Qty.	10 pc(s).	

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version
Order No.	1965700000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	

RJ45



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-RJ45-C	Version
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	

IE-BH-V01M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Hybrid**

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

**General ordering data**

Type	IE-BI-HYB-10P	Version
Order No.	1069010000	Flange insert, for flange insert, Hybrid
GTIN (EAN)	4032248823970	
Qty.	10 pc(s).	
Type	IE-BIC-HYB-P-0,5-300	Version
Order No.	1096150000	Crimp contact, for flange insert, Hybrid
GTIN (EAN)	4032248869114	
Qty.	300 pc(s).	

LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-BI-LCD-SM-C	Version
Order No.	1962880000	LC insert, Bulkhead insert LC duplex, singlemode
GTIN (EAN)	4032248645077	
Qty.	10 pc(s).	
Type	IE-BI-LCD-MM-C	Version
Order No.	1964420000	LC insert, Bulkhead insert LC duplex, multimode
GTIN (EAN)	4032248649037	
Qty.	10 pc(s).	