

**IE-BS-V01M-LCD-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connector sets according to IEC  
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.  
LC insert

**General ordering data**

Version	Flange FO, IP67, Version 1, LC Duplex coupling, Multimode
Order No.	<a href="#">1964440000</a>
Type	IE-BS-V01M-LCD-MM-C
GTIN (EAN)	4032248649051
Qty.	10 pc(s).

**IE-BS-V01M-LCD-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Depth	33.3 mm	Depth (inches)	1.311 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	60.1 g		

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Colour	Miscellaneous	Connection 1	LC Duplex
Connection 2		Description of article	Version 1, LC Duplex coupling
	LC Duplex		
Fibre type	Multimode	Housing main material	Zinc diecast
Insertion loss	≤ 0.4 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 30 dB

**General standards**

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-20
--------------------	---

**Classifications**

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18

**Approvals**

ROHS	Conform
------	---------

**IE-BS-V01M-LCD-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Downloads**

Approval/Certificate/Document of Conformity

[GOST Approval](#)

Engineering Data

[CAD data – STEP](#)

Product Change Notification

[Technical change to Bulkhead Variant 1 \(Metal\) - EN](#)[Technical change to Bulkhead Variant 1 \(Metal\) - DE](#)[20190724 Technische Änderung zu Flansch Variante 1 \(Metall\)](#)[20190724 Technische Änderung zu Flansch Variante 1 \(Metall\)](#)[20190724 Technical change to Bulkhead Variant 1 \(Metal\)](#)

User Documentation

[MAN IE GUIDE DE](#)[MAN IE GUIDE EN](#)[Designation key / Type key](#)[Manual](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)[PI PROFINET CABLING EN](#)[PI PROFINET CABLING EN](#)


## IE-BS-V01M-LCD-MM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

### Installation cut-out

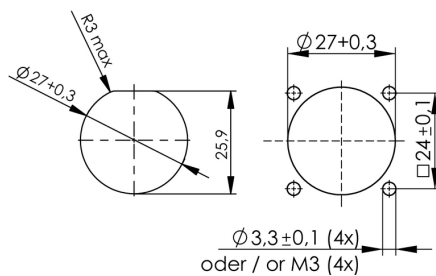

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

**IE-BS-V01M-LCD-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V01P	Version
Order No.	<a href="#">1965700000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	