

**IE-BS-V01M-SCRJ2SC-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connector sets according to IEC  
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.  
SC insert

**General ordering data**

Version	Flange FO, IP67, Version 1, coupling from SCRJ on 2*SC, Multimode
Order No.	<a href="#">1964450000</a>
Type	IE-BS-V01M-SCRJ2SC-MM-C
GTIN (EAN)	4032248649068
Qty.	10 pc(s).

**IE-BS-V01M-SCRJ2SC-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	36.6 mm	Depth (inches)	1.441 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	6.2 g		

**Temperatures**

Operating temperature	-40 °C...70 °C
-----------------------	----------------

**General data**

Colour	Miscellaneous	Connection 1	SC
Connection 2	SCRJ	Description of article	Version 1, coupling from SCRJ on 2*SC
Fibre type	Multimode	Housing main material	Zinc diecast
Insertion loss	≤ 0.4 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 30 dB

**General standards**

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-4, IEC 61754-24
--------------------	---

**Classifications**

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ECLASS 9.0	19-17-01-22	ECLASS 9.1	19-17-01-22
ECLASS 10.0	19-17-01-22	ECLASS 11.0	19-17-01-22
ECLASS 12.0	19-17-01-22	ECLASS 13.0	19-17-01-22

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18
RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c

**Approvals**

ROHS	Conform
------	---------

**IE-BS-V01M-SCRJ2SC-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Downloads**

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Product Change Notification	<a href="#">Technical change to Bulkhead Variant 1 (Metal) - EN</a> <a href="#">Technical change to Bulkhead Variant 1 (Metal) - DE</a> <a href="#">20190724 Technische Änderung zu Flansch Variante 1 (Metall)</a> <a href="#">20190724 Technische Änderung zu Flansch Variante 1 (Metall)</a> <a href="#">20190724 Technical change to Bulkhead Variant 1 (Metal)</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a>


## IE-BS-V01M-SCRJ2SC-MM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)


## Drawings

### Installation cut-out

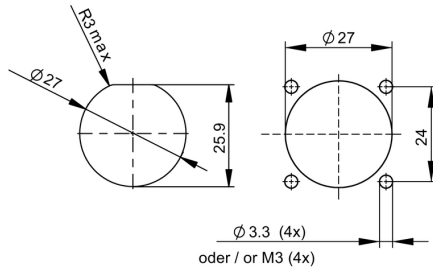

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

### Detailed drawing

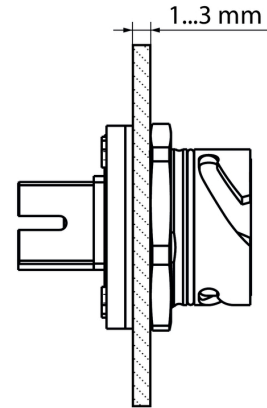

Wall thickness when using the central screw connection

**IE-BS-V01M-SCRJ2SC-MM-C****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Dust caps**

For protecting your devices against dust and dirt.

**General ordering data**

Type	IE-BP-V01P	Version
Order No.	<a href="#">1965700000</a>	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	