

IE-BS-V04P-SCRJ2SC-MM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with SC insert

General ordering data

Version	Flange FO, IP67, Version 4, coupling from SCRJ on 2*SC, Multimode, POF
Order No.	1964470000
Type	IE-BS-V04P-SCRJ2SC-MM-C
GTIN (EAN)	4032248649075
Qty.	10 pc(s).

IE-BS-V04P-SCRJ2SC-MM-C

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	48.3 mm	Depth (inches)	1.902 inch
Height	38 mm	Height (inches)	1.496 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	3.4 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Colour	Miscellaneous	Connection 1	SC
Connection 2	SCRJ	Description of article	Version 4, coupling from SCRJ on 2*SC
Fibre type	Multimode, POF	Housing main material	PA UL 94 V0
Insertion loss	≤ 0.4 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 30 dB

General standards

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-4, IEC 61754-24
--------------------	---

Classifications

ETIM 6.0	EC000752	ETIM 7.0	EC000752
ETIM 8.0	EC000752	ETIM 9.0	EC000752
ECLASS 9.1	19-17-01-16	ECLASS 10.0	19-17-01-16
ECLASS 11.0	19-17-01-16	ECLASS 12.0	19-17-01-16
ECLASS 13.0	19-17-01-16	ECLASS 14.0	19-17-01-16

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Approvals

ROHS	Conform
------	---------

Downloads

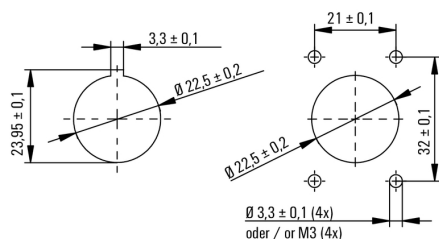
Approval/Certificate/Document of Conformity	GOST Approval PROFINET Manufacturer's Declaration
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN

IE-BS-V04P-SCRJ2SC-MM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Installation cut-out**

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

IE-BS-V04P-SCRJ2SC-MM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Blank**

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 pc(s).	

Dust caps

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V04P	Version
Order No.	1963900000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248646326	
Qty.	10 pc(s).	