

**TM-I 30 MM BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Process reliability: TM-I**

TM-I inlay tags have a guide tab which allows them to slide easily into the transparent sleeves from the type TM. Once the tag is in place, the tab is snapped off at the pre-determined break point. The ready-assembled sleeves can then be simply pushed over the conductors. Your benefits: large quantities can be efficiently pre-assembled in a single step.

**General ordering data**

|                    |   |
|--------------------|---|
| Version            | TM-I, Insert markers, 30 x 4 mm, blue                 |
| Order No.          | <a href="#">2005990000</a>                            |
| Type               | TM-I 30 MM BL   |
| GTIN (EAN)         | 4050118390452   |
| Qty.               | 2,000 pc(s).  |
| compatible printer | <a href="#">2599430000</a> <a href="#">2599440000</a> |

**TM-I 30 MM BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

|            |         |                 |            |
|------------|---------|-----------------|------------|
| Height     | 30 mm   | Height (inches) | 1.181 inch |
| Width      | 4 mm    | Width (inches)  | 0.157 inch |
| Net weight | 0.184 g |                 |            |

**Temperatures**

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

**General data**

|                                   |              |                                   |        |
|-----------------------------------|--------------|-----------------------------------|--------|
| Colour                            | blue         | Halogen                           | No     |
| Material                          | Polyester    | Number per roll                   | 2,000  |
| Operating temperature range       | -40...150 °C | Operating temperature range, max. | 150 °C |
| Operating temperature range, min. | -40 °C       | UL 94 flammability rating         | HB     |
| Width                             | 4 mm         |                                   |        |

**Conductor and cable markers**

|         |    |
|---------|----|
| Halogen | No |
|---------|----|

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001530    | ETIM 7.0    | EC001530    |
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ECLASS 9.0  | 27-40-04-01 | ECLASS 9.1  | 27-40-04-01 |
| ECLASS 10.0 | 27-40-04-01 | ECLASS 11.0 | 27-28-11-02 |
| ECLASS 12.0 | 27-28-11-02 | ECLASS 13.0 | 27-28-11-02 |

**Environmental Product Compliance**

|            |   |
|------------|---|
| REACH SVHC | / |
|------------|---|

**Approvals**

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

**Downloads**


|                  |  |
|------------------|--|
| Engineering Data | <a href="#">CAD data – STEP</a>          |
| Engineering Data | <a href="#">Zuken E3.S</a>               |
| Catalogues       | <a href="#">Catalogues in PDF-format</a> |

### TM-I 30 MM BL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

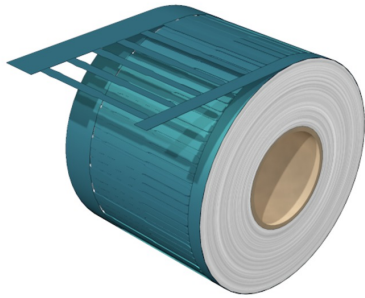

**TM-I 30 MM BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |
|------------|----------------------------|
| Type       | MM PLUS ROLLER 110         |
| Order No.  | <a href="#">2672590000</a> |
| GTIN (EAN) | 4050118708097              |
| Qty.       | 1 pc(s).                   |

**Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |            |
|------------|----------------------------|------------|
| Type       | RIBBON MM 76/360 SW        | Version    |
| Order No.  | <a href="#">2005080000</a> | Ink ribbon |
| GTIN (EAN) | 4050118389951              |            |
| Qty.       | 1 pc(s).                   |            |

## TM-I 30 MM BL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |
|------------|----------------------------|
| Type       | THM MMP ROLLER 115         |
| Order No.  | <a href="#">1357420000</a> |
| GTIN (EAN) | 4050118160314              |
| Qty.       | 1 pc(s).                   |