

ELS 6/30 MM WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**ELS**

ELS tags are special and non-adhesive insertable labels for WKM cable markers or for group tag carriers. The matt, thin but tear-resistant polyester provides very good labelling and excellent readability. Used in combination with water-repellent WKM sleeves, the solution guarantees particularly long-lasting identification of cables even in harsh environments.

General ordering data

Version	ELS, Insert markers, 30 x 6 mm, white
Order No.	2009980000
Type	ELS 6/30 MM WS
GTIN (EAN)	4050118396850
Qty.	3,000 pc(s).
compatible printer	2599430000 2599440000

ELS 6/30 MM WS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.14 mm	Depth (inches)	0.006 inch
Height	30 mm	Height (inches)	1.181 inch
Width	6 mm	Width (inches)	0.236 inch
Net weight	0.058 g		

Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

General data

Colour	white	Halogen	No
Material	Polyester	Number per roll	3,000
Operating temperature range	-40...150 °C	Operating temperature range, max.	150 °C
Operating temperature range, min.	-40 °C	UL 94 flammability rating	HB
Version	halogen-free	Width	6 mm

Conductor and cable markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	Zuken E3.S
Catalogues	Catalogues in PDF-format

ELS 6/30 MM WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings



ELS 6/30 MM WS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).

WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking.

Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

General ordering data

Type	WKM 8/30	Version
Order No.	1631910000	WKM, Conductor and cable markers, 7 - 115 mm, 30 x 8 mm, Wire
GTIN (EAN)	4008190206666	and cable markers, Transparent
Qty.	50 pc(s).	

ELS 6/30 MM WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

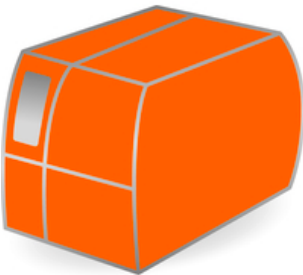
Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).