

HS 0.8-2.4/25 MM Y**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

| | |
|--------------------|--|
| Version | Conductor and cable markers, 0.8 - 2.4 mm, 25.4 x 4.2 mm, yellow |
| Order No. | 2437480000 |
| Type | HS 0.8-2.4/25 MM Y |
| GTIN (EAN) | 4050118461275 |
| Qty. | 2,000 pc(s). |
| compatible printer | 2599430000 2599440000 |

HS 0.8-2.4/25 MM Y**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | | | |
|------------|---------|-----------------|------------|
| Depth | 0.77 mm | Depth (inches) | 0.03 inch |
| Height | 25.4 mm | Height (inches) | 1 inch |
| Width | 4.2 mm | Width (inches) | 0.165 inch |
| Net weight | 0.228 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -55...135 °C |
|-----------------------------|--------------|

General data

| | | | |
|-----------------------------------|--------------|-----------------------------------|---|
| Colour | yellow | Halogen | Yes |
| Material | Polyolefine | Number per roll | 2,000 |
| Operating temperature range | -55...135 °C | Operating temperature range, max. | 135 °C |
| Operating temperature range, min. | -55 °C | Recommended industries | Plant manufacture, Energy, Device manufacturer, Machinery |
| Width | 4.2 mm | | |

Conductor and cable markers

| | | | |
|-----------------------------------|----------------------|----------------------------------|----------------------------|
| Conductor O.D. | 0.8 - 2.4 mm | Conductor O.D., max. | 2.4 mm |
| Conductor O.D., min. | 0.8 mm | Conductor cross-section, max. | 0.5 mm ² |
| Conductor cross-section, min. | 0.25 mm ² | Cross-section for connected wire | 0.25 - 0.5 mm ² |
| Halogen | Yes | Rate of shrinkage | 3:1 |
| Recommended shrinking temperature | 90 °C | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001530 | ETIM 7.0 | EC001530 |
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ECLASS 9.0 | 27-40-04-01 | ECLASS 9.1 | 27-40-04-01 |
| ECLASS 10.0 | 27-40-04-01 | ECLASS 11.0 | 27-28-11-02 |
| ECLASS 12.0 | 27-28-11-02 | ECLASS 13.0 | 27-28-11-02 |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| REACH SVHC | / |
| RoHS Compliance Status | Compliant without exemption |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|------------|--|
| Catalogues | Catalogues in PDF-format |
|------------|--|

HS 0.8-2.4/25 MM Y

Weidmüller Interface GmbH & Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

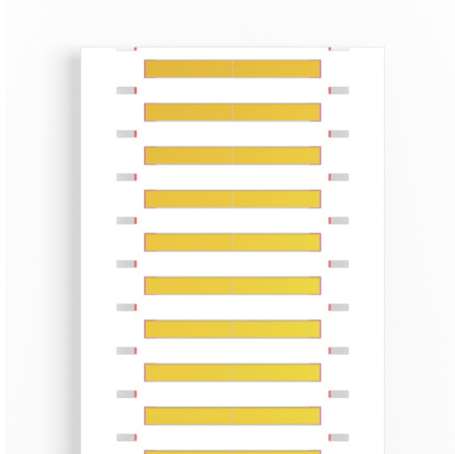

HS 0.8-2.4/25 MM Y**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | |
|------------|----------------------------|------------|
| Type | RIBBON MM-HS 60/300 SW | Version |
| Order No. | 2448880000 | Ink ribbon |
| GTIN (EAN) | 4050118462944 | |
| Qty. | 1 pc(s). | |

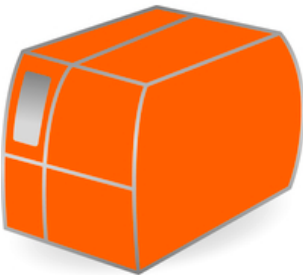THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | |
|------------|----------------------------|
| Type | MM PLUS ROLLER 110 |
| Order No. | 2672590000 |
| GTIN (EAN) | 4050118708097 |
| Qty. | 1 pc(s). |

HS 0.8-2.4/25 MM Y

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | |
|------------|----------------------------|
| Type | THM MMP ROLLER 115 |
| Order No. | 1357420000 |
| GTIN (EAN) | 4050118160314 |
| Qty. | 1 pc(s). |