

SAI-WDF 5P B M12 K**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration****General ordering data**

Order No.	2485310000
Type	SAI-WDF 5P B M12 K
GTIN (EAN)	4050118495942
Qty.	1 pc(s).

SAI-WDF 5P B M12 K

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	22 g
------------	------

Technical data customisable plug-in connectors

Cable glands	M 12	Coding	B-coded
Contact material	CuZn	Contact surface	Gold-plated
Housing main material	CuZn	Number of poles	5
Protection degree	IP67	Rated current	4 A
Rated voltage	60 V	Temperature range of housing	-40 ... +85 °C
Type of connection	Screw connection		

General technical specifications

Cable glands	M 12	Coding	B-coded
Connection thread	M12 socket, M12 plug	Contact material	CuZn
Contact surface	Gold-plated	Housing main material	CuZn
Number of poles	5	Protection degree	IP67
Rated current	4 A	Rated voltage	60 V
Temperature range of housing	-40 ... +85 °C	Type of connection	Screw connection

Classifications

ETIM 6.0	EC002925	ETIM 7.0	EC002925
ETIM 8.0	EC002925	ETIM 9.0	EC002925
ECLASS 9.0	27-44-01-06	ECLASS 9.1	27-44-01-06
ECLASS 10.0	27-44-01-06	ECLASS 11.0	27-44-01-06
ECLASS 12.0	27-44-01-06	ECLASS 13.0	27-44-01-06

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	22cbd99b-5f46-4c36-9938-bd61e241a9ab

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN

SAI-WDF 5P B M12 K

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany


www.weidmueller.com

Drawings

Dimensioned drawing

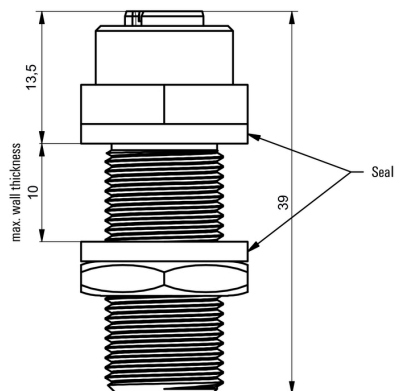

Pole scheme

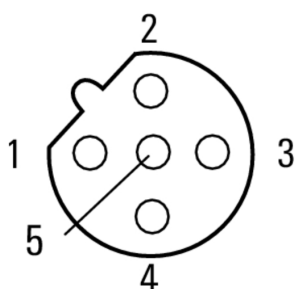

Pole scheme

