

SAI-WDF 4P M12 K 230**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration****General ordering data**

Order No.	2485360000
Type	SAI-WDF 4P M12 K 230
GTIN (EAN)	4050118496048
Qty.	1 pc(s).

SAI-WDF 4P M12 K 230

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	23 g
------------	------

Technical data customisable plug-in connectors

Coding	A-coded	Contact material	CuZn
Contact surface	Gold-plated	Housing main material	CuZn
Number of poles	4	Protection degree	IP67
Rated current	4 A	Rated voltage	230 V
Temperature range of housing	-40 ... +85 °C	Type of connection	Screw connection

General technical specifications

Coding	A-coded	Connection thread	M12 socket, M12 plug
Contact material	CuZn	Contact surface	Gold-plated
Housing main material	CuZn	Number of poles	4
Protection degree	IP67	Rated current	4 A
Rated voltage	230 V	Temperature range of housing	-40 ... +85 °C
Type of connection	Screw connection		

Classifications

ETIM 6.0	EC002925	ETIM 7.0	EC002925
ETIM 8.0	EC002925	ETIM 9.0	EC002925
ECLASS 9.0	27-44-01-06	ECLASS 9.1	27-44-01-06
ECLASS 10.0	27-44-01-06	ECLASS 11.0	27-44-01-06
ECLASS 12.0	27-44-01-06	ECLASS 13.0	27-44-01-06

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	22cbd99b-5f46-4c36-9938-bd61e241a9ab

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN


SAI-WDF 4P M12 K 230

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings


Dimensioned drawing

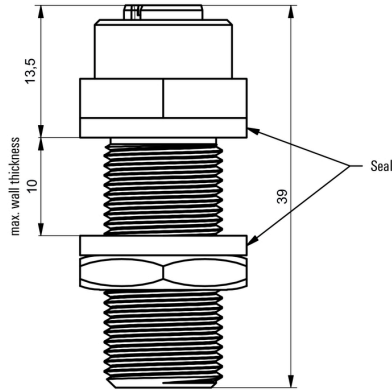

Dimensioned drawing

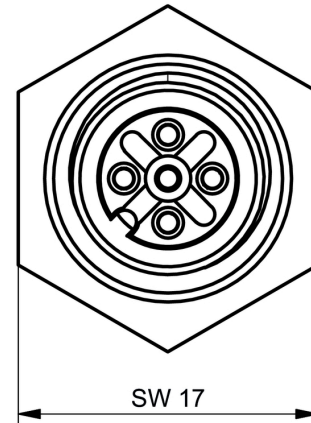

Pole scheme

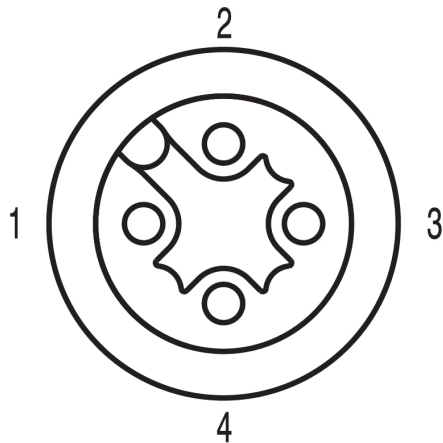

Pole scheme

