

**THM ET 55/55 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The THM labels offer brilliant printing quality thanks to the thermal transfer technology. Different materials and the user-friendly printing system M-Print® PRO under Windows optimise all labelling efforts.

- High-quality polyester labels in different colours
- Due to their flexible material and the thick adhesive layer, the THM GEW can be used on angled or round objects such as cables or hoses
- Roll-packaged THM ET S7 can be used to label the Simatic 200S, S7-300 and S7-400 modules from Siemens
- Labels are automatically positioned in the printer for perfectly centred prints on each label.
- Labelling with the THM MultiMark or THM MultiMark Plus thermal transfer printers

**General ordering data**

Version	Conductor and cable markers, 55 x 55 mm, white
Order No.	<a href="#">2539380000</a>
Type	THM ET 55/55 WS
GTIN (EAN)	4050118570144
Qty.	1,000 pc(s).

**THM ET 55/55 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	0.35 mm	Depth (inches)	0.014 inch
Height	55 mm	Height (inches)	2.165 inch
Width	55 mm	Width (inches)	2.165 inch
Net weight	1.216 g		

**Temperatures**

Operating temperature range	-50...100 °C	Continuous operating temp., min.	-50
Continuous operating temp., max.	100		

**General data**

Colour	white	Halogen	No
Material	Polypropylene	Operating temperature range	-50...100 °C
Operating temperature range, max.	100 °C	Operating temperature range, min.	-50 °C
UL 94 flammability rating	HB	Width	55 mm

**Conductor and cable markers**

Halogen	No
---------	----

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Approvals**

ROHS	Conform
------	---------

**Downloads**


Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

**THM ET 55/55 WS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

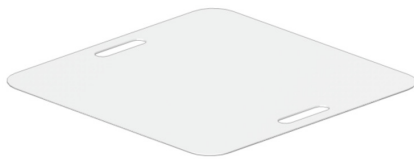

**THM ET 55/55 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-HS 60/300 SW	Version
Order No.	<a href="#">2448880000</a>	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 pc(s).	