

**CMA-CTM-7-50-1A-0.4VA-1****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

similar to the product

The CMA-CTM 7 series mini current transformer is an inductive current transformer designed according to the transformer principle for circular primary conductors.

The CMA-CTM 7 series current transformers are maintenance-free and is designed for measuring primary currents in the range 32 A to 64 A. This is converted into a current up to 1 A on the secondary side.

With its small dimensions, it perfectly suits applications in a 3-phase circuit breaker with a phase separation of 17.5 mm.

**General ordering data**

Version	Primary current: 50 A, Secondary current max.: 1 A, Load: 0.4 VA, Tolerance class: 1, closed current transformer
Order No.	<a href="#">2556030000</a>
Type	CMA-CTM-7-50-1A-0.4VA-1
GTIN (EAN)	4050118566406
Qty.	1 pc(s).
Manufacturer	MBS AG

## CMA-CTM-7-50-1A-0.4VA-1

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	19 mm	Depth (inches)	0.748 inch
Height	46.5 mm	Height (inches)	1.831 inch
Width	27.5 mm	Width (inches)	1.083 inch
Net weight	64 g		

## Temperatures

Storage temperature	-25 °C...70 °C	Operating temperature	-5 °C...50 °C
---------------------	----------------	-----------------------	---------------

## Dimensions of live conductors

Type of conductor	Insulated conductor only	Round conductor	7.6 mm
Installation location	Indoor use		

## Electrical attributes

Load	0.4 VA	Primary current	50 A
Secondary current	0...1 A	Tolerance class	1

## Technical properties

Insulation class	E	Nominal frequency	50 Hz
Thermal rated continuous current $I_{\text{thermal}}$	$1.0 \times I_{\text{rated}}$		

## Insulation coordination

Standard	IEC 61869-1: 2007, IEC 61869-2: 2012	Tolerance class	1
----------	--------------------------------------	-----------------	---

## Classifications

ETIM 6.0	EC002048	ETIM 7.0	EC002048
ETIM 8.0	EC002048	ETIM 9.0	EC002048
ECLASS 9.0	27-21-09-02	ECLASS 9.1	27-21-09-02
ECLASS 10.0	27-21-09-02	ECLASS 11.0	27-21-09-02
ECLASS 12.0	27-21-09-02	ECLASS 13.0	27-21-09-02
ECLASS 14.0	27-21-09-02		

## Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant

## Approvals

ROHS	Conform
------	---------

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">UL- certificate</a> <a href="#">Declaration of Conformity</a> <a href="#">UKCA Declaration of Conformity</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">Device description – Betriebsanleitung deutsch</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>



Creation date August 29, 2024 8:36:47 PM CEST

## CMA-CTM-7-50-1A-0.4VA-1

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

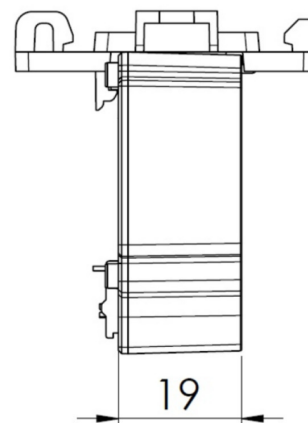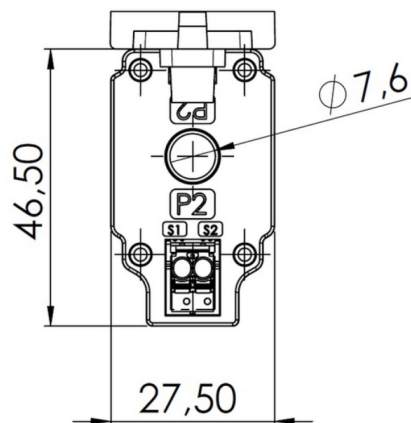

**CMA-CTM-7-50-1A-0.4VA-1****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Mini current transformer**

The CMA-CTM 7 series mini current transformer is an inductive current transformer designed according to the transformer principle for circular primary conductors.

The CMA-CTM 7 series current transformers are maintenance-free and is designed for measuring primary currents in the range 32 A to 64 A. This is converted into a current up to 1 A on the secondary side.

With its small dimensions, it perfectly suits applications in a 3-phase circuit breaker with a phase separation of 17.5 mm.

**General ordering data**

Type	CMA-CTM-7-SNAP-ON
Order No.	<a href="#">2525160000</a>
GTIN (EAN)	4050118536522
Qty.	1 pc(s).