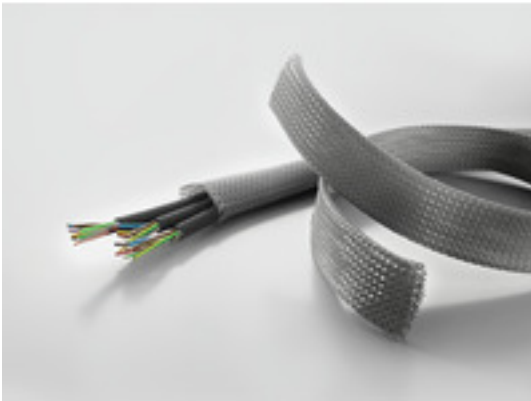


CBC-FB 50-75/50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

Spiral and webbing hoses are particularly suitable for the construction of space-saving cable routing systems in switch gears and control cabinets. They are used for guiding, protecting and bundling cables and wires - for example, in the transition between the enclosure interior and the door.

General ordering data

Version	Fabric of protective cable hose
Order No.	2588860000
Type	CBC-FB 50-75/50
GTIN (EAN)	4050118600360
Qty.	50 m

CBC-FB 50-75/50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Length	50,000 mm	Length (inches)	1,968.5 inch
Diameter	75 mm	Net weight	32 g

Temperatures

Operating temperature range	-50...150 °C
-----------------------------	--------------

General information

Bundle diameter, max.	75 mm	Bundle diameter, min.	50 mm
Colour	Silver grey	Diameter	75 mm
Material	Polyethylene terephthalate PET	Nominal diameter	50 mm
Operating temperature range	-50...150 °C	UL 94 flammability rating	HB
Usable cross-section	4,417 mm ²		

Classifications

ETIM 6.0	EC002604	ETIM 7.0	EC002604
ETIM 8.0	EC002604	ETIM 9.0	EC002604
ECLASS 9.1	27-43-03-02	ECLASS 10.0	27-43-03-02
ECLASS 11.0	27-43-03-02	ECLASS 12.0	27-43-03-02
ECLASS 13.0	27-43-03-02		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--