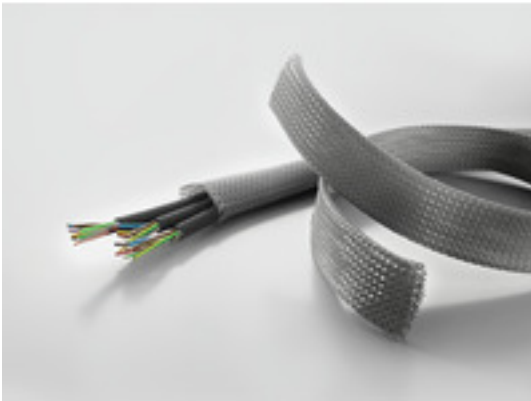


**CBC-FB 30-45/100****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Similar to illustration**

Spiral and webbing hoses are particularly suitable for the construction of space-saving cable routing systems in switch gears and control cabinets. They are used for guiding, protecting and bundling cables and wires - for example, in the transition between the enclosure interior and the door.

**General ordering data**

Version	Fabric of protective cable hose
Order No.	<a href="#">2588880000</a>
Type	CBC-FB 30-45/100
GTIN (EAN)	4050118602432
Qty.	100 m

**CBC-FB 30-45/100****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Length	100,000 mm	Length (inches)	3,937 inch
Diameter	45 mm	Net weight	25 g

**Temperatures**

Operating temperature range	-50...150 °C
-----------------------------	--------------

**General information**

Bundle diameter, max.	45 mm	Bundle diameter, min.	30 mm
Colour	Silver grey	Diameter	45 mm
Material	Polyethylene terephthalate PET	Nominal diameter	30 mm
Operating temperature range	-50...150 °C	UL 94 flammability rating	HB
Usable cross-section	1,590 mm <sup>2</sup>		

**Classifications**

ETIM 6.0	EC002604	ETIM 7.0	EC002604
ETIM 8.0	EC002604	ETIM 9.0	EC002604
ECLASS 9.1	27-43-03-02	ECLASS 10.0	27-43-03-02
ECLASS 11.0	27-43-03-02	ECLASS 12.0	27-43-03-02
ECLASS 13.0	27-43-03-02		

**Environmental Product Compliance**

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--