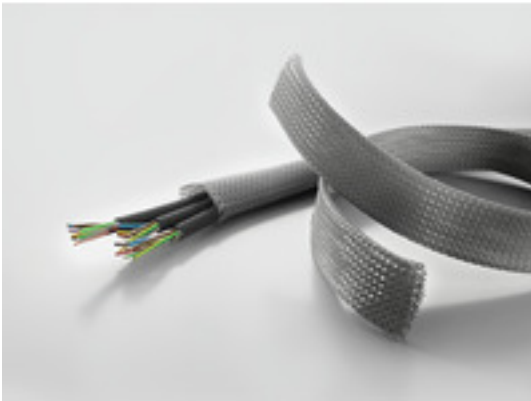


CBC-FB 20-30/100**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

Spiral and webbing hoses are particularly suitable for the construction of space-saving cable routing systems in switch gears and control cabinets. They are used for guiding, protecting and bundling cables and wires - for example, in the transition between the enclosure interior and the door.

General ordering data

Version	Fabric of protective cable hose
Order No.	2588900000
Type	CBC-FB 20-30/100
GTIN (EAN)	4050118602470
Qty.	100 m

CBC-FB 20-30/100**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Length	100,000 mm	Length (inches)	3,937 inch
Diameter	30 mm	Net weight	17 g

Temperatures

Operating temperature range	-50...150 °C
-----------------------------	--------------

General information

Bundle diameter, max.	30 mm	Bundle diameter, min.	20 mm
Colour	Silver grey	Diameter	30 mm
Material	Polyethylene terephthalate PET	Nominal diameter	20 mm
Operating temperature range	-50...150 °C	UL 94 flammability rating	HB
Usable cross-section	706 mm ²		

Classifications

ETIM 6.0	EC002604	ETIM 7.0	EC002604
ETIM 8.0	EC002604	ETIM 9.0	EC002604
ECLASS 9.1	27-43-03-02	ECLASS 10.0	27-43-03-02
ECLASS 11.0	27-43-03-02	ECLASS 12.0	27-43-03-02
ECLASS 13.0	27-43-03-02	ECLASS 14.0	27-43-03-02

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	--