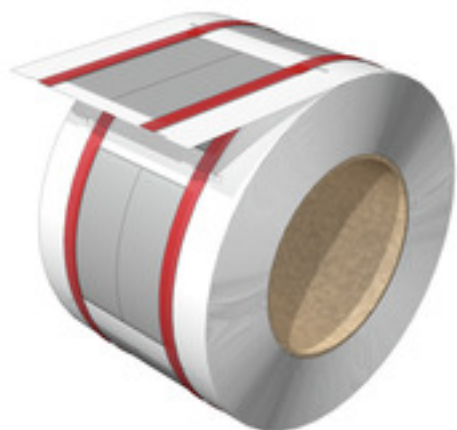


**HS-FR 19.1-38.1/25 MM W****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

**General ordering data**

|                    |  |
|--------------------|--|
| Version            | Conductor and cable markers, 19.1 - 38.1 mm, 24.9 x 60.8 mm, white |
| Order No.          | <a href="#">2621720000</a>   |
| Type               | HS-FR 19.1-38.1/25 MM W  |
| GTIN (EAN)         | 4050118625325  |
| Qty.               | 200 pc(s).   |
| compatible printer | <a href="#">2599430000</a> <a href="#">2599440000</a>              |

## HS-FR 19.1-38.1/25 MM W

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

### Dimensions and weights

|            |         |                 |            |
|------------|---------|-----------------|------------|
| Depth      | 0.77 mm | Depth (inches)  | 0.03 inch  |
| Height     | 24.9 mm | Height (inches) | 0.98 inch  |
| Width      | 60.8 mm | Width (inches)  | 2.394 inch |
| Net weight | 2.35 g  |                 |            |

### Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -55...125 °C |
|-----------------------------|--------------|

### General data

|                                   |                |                                   |              |
|-----------------------------------|----------------|-----------------------------------|--------------|
| Colour                            | white          | Halogen                           | No           |
| Material                          | Polyolefine    | Operating temperature range       | -55...125 °C |
| Operating temperature range, max. | 125 °C         | Operating temperature range, min. | -55 °C       |
| Size of labelling field           | 60.8 x 24.9 mm | Width                             | 60.8 mm      |

### Conductor and cable markers

|   |                    |   |                          |
|---|--------------------|---|--------------------------|
| Conductor O.D.                          | 19.1 - 38.1 mm     | Conductor O.D., max.                    | 38.1 mm                  |
| Conductor O.D., min.                    | 19.1 mm            | Conductor cross-section, max.           | 240 mm <sup>2</sup>      |
| Conductor cross-section, min.           | 70 mm <sup>2</sup> | Cross-section for connected wire        | 70 - 240 mm <sup>2</sup> |
| Halogen                                 | No                 | Rate of shrinkage                       | 2:1                      |
| Recommended shrinking temperature       | 90 °C              | Wire connection cross section AWG, max. | AWG 450 MCM              |
| Wire connection cross section AWG, min. | AWG 2/0            |   |                          |

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001530    | ETIM 7.0    | EC001530    |
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ECLASS 9.0  | 27-40-04-01 | ECLASS 9.1  | 27-40-04-01 |
| ECLASS 10.0 | 27-40-04-01 | ECLASS 11.0 | 27-28-11-02 |
| ECLASS 12.0 | 27-28-11-02 | ECLASS 13.0 | 27-28-11-02 |
| ECLASS 14.0 | 27-28-11-02 |             |             |

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| REACH SVHC             | /                           |
| RoHS Compliance Status | Compliant without exemption |

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Downloads

|            |  |
|------------|--|
| Catalogues | <a href="#">Catalogues in PDF-format</a> |
|------------|--|

### HS-FR 19.1-38.1/25 MM W

**Weidmüller Interface GmbH & Co. KG**


Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

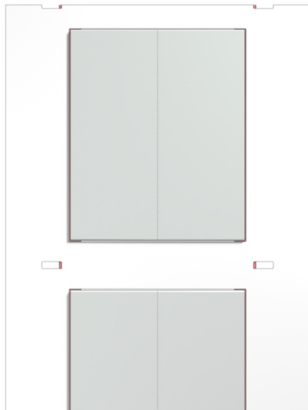

**HS-FR 19.1-38.1/25 MM W****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold


Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |            |
|------------|----------------------------|------------|
| Type       | RIBBON MM-HS 60/300 SW     | Version    |
| Order No.  | <a href="#">2448880000</a> | Ink ribbon |
| GTIN (EAN) | 4050118462944              |            |
| Qty.       | 1 pc(s).                   |            |

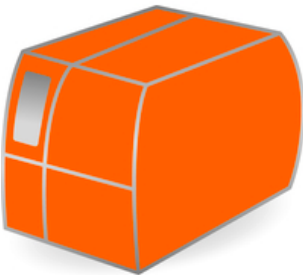**THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |
|------------|----------------------------|
| Type       | MM PLUS ROLLER 110         |
| Order No.  | <a href="#">2672590000</a> |
| GTIN (EAN) | 4050118708097              |
| Qty.       | 1 pc(s).                   |


## HS-FR 19.1-38.1/25 MM W

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### THM MULTIMARK

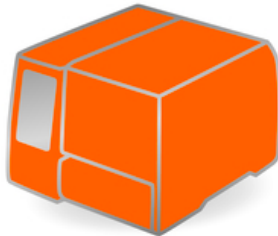

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

|            |                            |
|------------|----------------------------|
| Type       | THM MMP ROLLER 115         |
| Order No.  | <a href="#">1357420000</a> |
| GTIN (EAN) | 4050118160314              |
| Qty.       | 1 pc(s).                   |