

HDC MHP70 F 10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

General ordering data

| | |
|------------|---|
| Version | Female, silver, 10 - 10 mm ² |
| Order No. | 2668200000 |
| Type | HDC MHP70 F 10 |
| GTIN (EAN) | 4050118803006 |
| Qty. | 10 pc(s). |

HDC MHP70 F 10**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | |
|------------|-------|
| Net weight | 7.2 g |
|------------|-------|

General data

| | | | |
|----------------------------------|-------------------------|------------------------------------|--------------------|
| Conductor cross-section, max. | 10 mm ² | Conductor cross-section, min. | 10 mm ² |
| Cross-section for connected wire | 10 - 10 mm ² | Material | Copper alloy |
| Plugging cycles | ≥ 500 | Production methods | turned |
| Series | ModuPlug | Stripping length, rated connection | 16 mm |
| Surface finish | silver | Type | Female |
| Type of connection | Crimp connection | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC000796 | ETIM 7.0 | EC000796 |
| ETIM 8.0 | EC000796 | ETIM 9.0 | EC000796 |
| ECLASS 9.0 | 27-44-02-04 | ECLASS 9.1 | 27-44-02-04 |
| ECLASS 10.0 | 27-44-02-04 | ECLASS 11.0 | 27-44-02-04 |
| ECLASS 12.0 | 27-44-02-04 | ECLASS 13.0 | 27-44-02-04 |

Environmental Product Compliance

| | |
|--------------------------------------|--------------------------------------|
| REACH SVHC | Lead 7439-92-1 |
| SCIP | 6eabd5ae-2d6b-409e-8bdf-87c27ee10e40 |
| RoHS Compliance Status | Compliant with exemption |
| RoHS Exemption (if applicable/known) | 6c |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads


| | |
|------------------|--|
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |

HDC MHP70 F 10

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

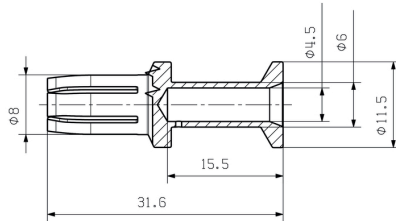

HDC MHP70 F 10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

... for compression cable lugs

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

| | | |
|------------|----------------------------|---------------------------------------|
| Type | ES EPG/HPG 60 HEX 10 | Version |
| Order No. | 2505160000 | Crimping tool insert, Hexagonal crimp |
| GTIN (EAN) | 4050118519556 | |
| Qty. | 1 pc(s). | |

... for compression cable lugs (acc. to DIN 46235)

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

| | | |
|------------|----------------------------|-----------------|
| Type | ES EPG 45 HEX 10/70 | Version |
| Order No. | 1500940000 | Hexagonal crimp |
| GTIN (EAN) | 4050118309522 | |
| Qty. | 1 pc(s). | |

HDC MHP70 F 10

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tools

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

| | | |
|------------|----------------------------|--|
| Type | EPG 45 | Version |
| Order No. | 1500830000 | Pressing tool, 6mm ² , 150mm ² , Hexagonal crimp, WM crimp, Indent |
| GTIN (EAN) | 4050118309317 | crimp, Trapezoidal crimp, Oval crimping |
| Qty. | 1 pc(s). | |

Tools

**Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts**

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB

General ordering data

| | | |
|------------|----------------------------|--|
| Type | HPG 60 | Version |
| Order No. | 2453820000 | 6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp, |
| GTIN (EAN) | 4050118468427 | Trapezoidal crimp, Oval crimping |
| Qty. | 1 pc(s). | |