

IE-FC-DFM-KNOB-4X**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Version	FrontCom, Double frame, Metal cover, Control knob locking, NEMA 4X
Order No.	2669640000
Type	IE-FC-DFM-KNOB-4X
GTIN (EAN)	4050118800531
Qty.	1 pc(s).

IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	27.5 mm	Depth (inches)	1.083 inch
Height	134 mm	Height (inches)	5.276 inch
Width	132 mm	Width (inches)	5.197 inch
Wall thickness, min.	1 mm	Wall thickness, max.	5 mm
Net weight	824.97 g		

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Material cover	Zinc diecast, powder-coated	Material frame	Zinc diecast, powder-coated
Product type	Double frame, Metal cover, Control knob locking, NE-MA 4X	Protection class (UL)	Type 4X
Protection degree	IP65, in closed state		

General standards

Certificate No. (CSA)	2000039-80039714	Certificate No. (DNV)	TAA000022B
Certificate No. (cURus)	E223801		

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-90
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-28-92	ECLASS 13.0	27-18-28-92

Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (cURus)	E223801

Downloads

Engineering Data	CAD data – STEP
User Documentation	Designation key / Type key
Catalogues	Catalogues in PDF-format


IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

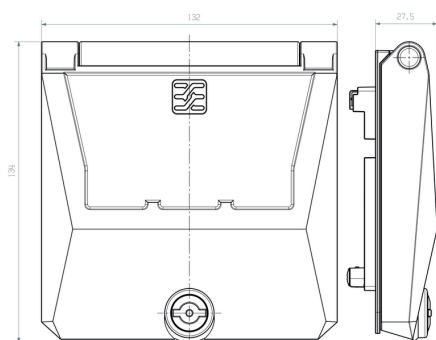


Unit: mm

Installation cut-out



Unit: mm

Dimensioned drawing

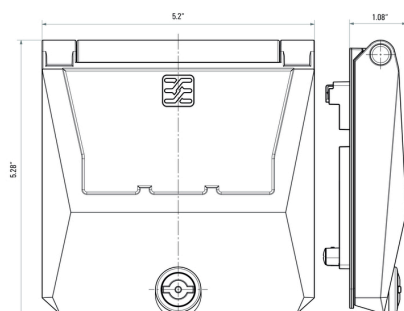

Unit: in

Installation cut-out



Unit: in

IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank, adhesive backing



SM is a MultiCard marker for labelling control and signalling devices. The tags are clipped into the carriers or attached by means of the adhesive film already fitted to them. Customised tags can be created with the PrintJet CONNECT or Plotter marking systems.

- Users can quickly produce tags to suit their needs
- No need to stock expensive standard tags
- Highly resistant printing quality when using the PrintJet as a substitute for engraving
- For extreme demands, we recommend the ETO SM protective film
- Holders can be used for the 22-mm or 30-mm-diameter push-buttons from Siemens, ABB, Moeller and Télémécanique

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	SM 27/18 K MC NE GR	Version
Order No.	1073340000	SwitchMark, Device markers, 18 x 27 mm, grey
GTIN (EAN)	4032248831425	
Qty.	80 pc(s).	
Type	SM 27/18 K MC NE WS	Version
Order No.	1707270000	SwitchMark, Device markers, 18 x 27 mm, white
GTIN (EAN)	4008190925116	
Qty.	80 pc(s).	
Type	SM 27/18 K MC NE SI	Version
Order No.	1713760000	SwitchMark, Device markers, 18 x 27 mm, silver
GTIN (EAN)	4008190331177	
Qty.	80 pc(s).	

IE-FC-DFM-KNOB-4X

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 7/20 SIRIUS MC NE WS	Version
Order No.	1736181044	ESG, Device markers x 20 mm, PA 66, Colour: white, pluggable
GTIN (EAN)	4008190985950	
Qty.	200 pc(s).	

Accessories for FrontCom Vario



General ordering data

Type	IE-FC-KEY	Version
Order No.	1465930000	FrontCom, spare key, Single frame, Miscellaneous
GTIN (EAN)	4050118272314	
Qty.	1 pc(s).	
Type	IE-FC-PWPC	Version
Order No.	1450820000	FrontCom, Touch-safe protection
GTIN (EAN)	4050118255584	
Qty.	1 pc(s).	