

IE-PS-VAPM-5P-2.5-50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull Power plug-in connector according to PROFINET specification

General ordering data

Version	Power connector, Plug, PROFINET, Set of connectors
Order No.	2682090000
Type	IE-PS-VAPM-5P-2.5-50
GTIN (EAN)	4050118707427
Qty.	50 pc(s).

IE-PS-VAPM-5P-2.5-50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	97.4 g
------------	--------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Cable sealing material	EPDM	Colour	Silver grey
Connection 1	PushPull Power	Connection 2	Tension clamp
Contact material	Cu-alloy	Contact surface	Gold over nickel
Housing main material	Zinc diecast, nickel-plated	Number of poles	5
Plugging cycles	≥ 100	Pollution severity	2
Protection degree	IP65, IP67	Sealing material	NBR
Sheath diameter, max.	13 mm	Sheath diameter, min.	8 mm
Shielding	unshielded	Type of interlock	Push Pull
UL 94 flammability rating	V-2	Wire connection cross section, finely stranded, max.	2.5 mm ²
Wire connection cross section, finely stranded, min.	0.75 mm ²		

Electrical properties

Current-carrying capacity at 50 °C	16 A	Operating voltage	24 V
------------------------------------	------	-------------------	------

General standards

Connector standard	in accordance with PROFINET specification, IEC 61076-3-126
--------------------	--

Standards

Connector standard	in accordance with PROFINET specification, IEC 61076-3-126
--------------------	--

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90

Important note

Product information	For cables with outer diameter 6-8 mm, order additional reducing seal.
---------------------	--

Approvals

ROHS	Conform
------	---------

IE-PS-VAPM-5P-2.5-50

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Product Change Notification	Technische Änderung der Bedruckung auf PushPull Power Kontakteinsätzen Technical change to printing on PushPull Power contact inserts
User Documentation	Manual
Catalogues	Catalogues in PDF-format


IE-PS-VAPM-5P-2.5-50

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Dimensioned drawing

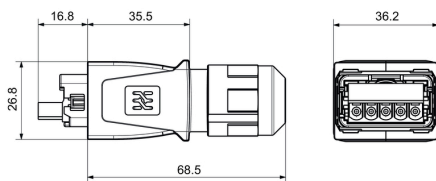

Drawing

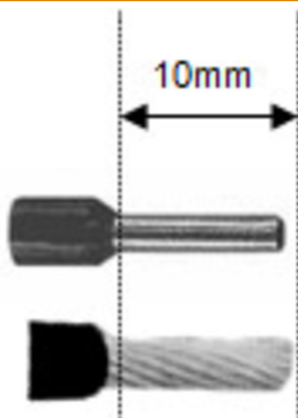

When using wire-end-ferrules, we recommend the length of 10 mm.

IE-PS-VAPM-5P-2.5-50**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Individual parts**

PushPull Power plug-in connector according to PROFINET specification

General ordering data

Type	IE-REDU-6-8-PS-VAPM	Version
Order No.	2531330000	Power connector, Plug, Sealing insert, PROFINET
GTIN (EAN)	4050118545227	
Qty.	10 pc(s).	