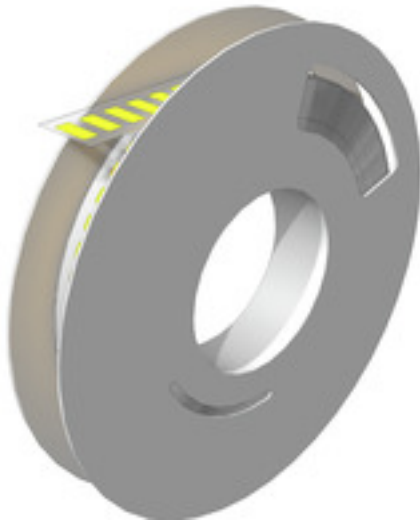


**ESG-LP 6/15 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

**Your benefits with MultiMark**

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

**General ordering data**

Version	ESG, Device markers, 6 x 15 mm, yellow
Order No.	<a href="#">2711850000</a>
Type	ESG-LP 6/15 MM GE
GTIN (EAN)	4050118750089
Qty.	24,000 pc(s).
compatible printer	<a href="#">2878190000</a>

## ESG-LP 6/15 MM GE

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	6 mm	Height (inches)	0.236 inch
Width	15 mm	Width (inches)	0.591 inch
Net weight	0.025 g		

## Temperatures

Operating temperature range	-40...150 °C
-----------------------------	--------------

## General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	yellow	Halogen	No
Material	Polyester	Operating temperature range	-40...150 °C
Operating temperature range, max.	150 °C	Operating temperature range, min.	-40 °C
Printed characters	without	Size of labelling field	6 x 15 mm
UL 94 flammability rating	V-0	Version	Self-adhesive, halogen-free
Width	15 mm		

## Device markers

Halogen	No
---------	----

## Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

## Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

## Approvals

ROHS	Conform
------	---------

## Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**ESG-LP 6/15 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



**ESG-LP 6/15 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	<a href="#">2005090000</a>	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 pc(s).	

**THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	THM MMP EXT.RH
Order No.	<a href="#">1302920000</a>
GTIN (EAN)	4050118102307
Qty.	1 pc(s).