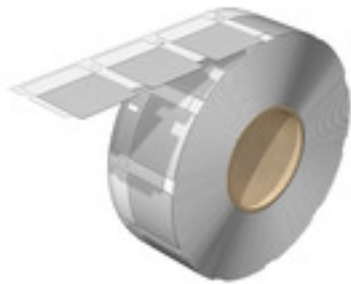


**THM WO-Q VIN 25/31.8 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

THM WriteOn cable markers on reels are used for labelling conductors and cables with an outside diameter of up to 36 mm. The transparent adhesive strip fixes and protects the printing on the marker surface.

- Protection of the marking against dirt and abrasion by wrapping it with the transparent adhesive strip
- Simple and quick printing with the high-quality thermal transfer printers

**General ordering data**

Version	THM, Conductor and cable markers, 3.9 - 7.8 mm, 25 x 31.8 mm, white
Order No.	<a href="#">2711920000</a>
Type	THM WO-Q VIN 25/31.8 WS
GTIN (EAN)	4050118750010
Qty.	1,000 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a>

## THM WO-Q VIN 25/31.8 WS

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	25 mm	Height (inches)	0.984 inch
Width	31.8 mm	Width (inches)	1.252 inch
Net weight	0.189 g		

## Temperatures

Operating temperature range	-40...80 °C
-----------------------------	-------------

## General data

Adhesive	Polyacrylate adhesive	
Approval acc. to UL 969	Yes	
Colour	white	
Halogen	Yes	
Material	Vinyl film	
Number of markers per combination	1 Label reel = Conductor and cable markers	
Number of markers per packaging unit	Form of supply	Label reel
Number per roll	1,000	
Operating temperature range	-40...80 °C	
Operating temperature range, max.	80 °C	
Operating temperature range, min.	-40 °C	
Orientation of print	horizontal and vertical	
Printed characters	without	
Type of printing	neutral	
UL 94 flammability rating	V-0	
Width	31.8 mm	

## Conductor and cable markers

Conductor O.D.	3.9 - 7.8 mm	Conductor O.D., max.	7.8 mm
Conductor O.D., min.	3.9 mm	Halogen	Yes

## Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

## Environmental Product Compliance

REACH SVHC	/
------------	---

## Approvals

ROHS	Conform
------	---------

## Downloads

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

**THM WO-Q VIN 25/31.8 WS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**



**THM WO-Q VIN 25/31.8 WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM 110/360 SW	Version
Order No.	<a href="#">2005070000</a>	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	
Type	RIBBON MM 76/360 SW	Version
Order No.	<a href="#">2005080000</a>	Ink ribbon
GTIN (EAN)	4050118389951	
Qty.	1 pc(s).	