

CH-HLAA-HLAB-24-0200-AG**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**IP65**
1.5 mm²

Product similar to illustration

The increasingly networked industrial world goes hand in hand with the modularization of machines and systems. Functions from the control cabinet are increasingly being moved to field level, which drives up the amount of cabling required.

Our ready-for-connection cable assemblies can be used wiring in field level and for transmitting data or power in various applications. The Plug & Produce solution by Weidmüller are fully tested and will lead to simplification of assembly on your machine. This allows you to focus on your core competencies and further increase your efficiency.

With our broad product portfolio of certified components, we offer you a wide diversification so that we can provide you the perfect solution for your application.

If you cannot find the cable assembly you are looking for despite our continuously growing portfolio, we can also offer you different length variants and customer-specific solutions.

General ordering data

Version	Heavy duty connector assemblies, Pin, Socket connector, Lapp ÖLFLEX® CLASSIC 110 BK 25G1.5 or similar, Shielded: No, Number of poles: 24
Order No.	2712360200
Type	CH-HLAA-HLAB-24-0200-AG
GTIN (EAN)	4050118750454
Qty.	1 pc(s).

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	1,559.4 g
------------	-----------

Temperatures

Limit temperature	-40 °C ... 80 °C
-------------------	------------------

Technical specifications for cable

Bending radius, min., moving	10 x cable diameter	Bending radius, min., stationary	4 x cable diameter
Cable length	2 m	Core cross-section	1.5 mm ²
Halogen	Yes	Insulation	PVC
Number of poles	24	Sheath material	PVC
Sheathing colour	black	Shielded	No
Temperature range, moving	-15...70 °C	Temperature range, stationary	-40...80 °C

General technical data

Protection degree	IP65	Rated voltage	500 V
Version	Pin, Socket connector		

General Technical Data

Number of poles	24	Pin arrangement	1:1, numbered cores
Protection degree	IP65	Rated voltage	500 V

Technical Specifications Connector

Connector	Connector description	Connector 1
	Cable entry	angled
	Housing main material	Diecast aluminium
	Series	HE
	Size	8
	Type	Pin
	Individual components connector	HDC 24B TSB U 1M25G HDC HE 24 MP H1.5/14 R VGM25-MS68 11-20 BG
	Connector description	Connector 2
	Cable entry	angled
	Housing main material	Diecast aluminium
	Series	HE
	Size	8
	Type	Female
	Individual components connector	HDC 24B TSB U 1M25G HDC HE 24 FP H1.5/14 R VGM25-MS68 11-20 BG

Technical specifications for cable

Bending radius, min., moving	10 x cable diameter	Bending radius, min., stationary	4 x cable diameter
Cable length	2 m	Core cross-section	1.5 mm ²
Halogen	Yes	Insulation	PVC
Line type	Lapp ÖLFLEX® CLASSIC 110 BK 25G1.5 or similar	Sheath material	PVC
Sheathing colour	black	Shielded	No
Temperature range, moving	-15...70 °C	Temperature range, moving, max.	70 °C
Temperature range, moving, min.	-15 °C	Temperature range, stationary	-40...80 °C
Temperature range, stationary, max.	80 °C	Temperature range, stationary, min.	-40 °C

Creation date June 5, 2024 6:48:48 AM CEST

Catalogue status 01.06.2024 / We reserve the right to make technical changes.

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data**Classifications**

ETIM 6.0	EC001576	ETIM 7.0	EC001576
ETIM 8.0	EC001576	ETIM 9.0	EC001576
ECLASS 9.0	27-06-04-02	ECLASS 9.1	27-06-91-90
ECLASS 10.0	27-06-04-02	ECLASS 11.0	27-06-04-02
ECLASS 12.0	27-06-04-02	ECLASS 13.0	27-06-04-02

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 Potassium perfluorobutane sulfonate 29420-49-3
SCIP	81ca46c4-2930-4739-aa54-e07d33c98f2c

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	------------------------------------------

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B SBU 2M25G	Version
Order No.	1787870000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard,
GTIN (EAN)	4032248205318	Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG29G	Version
Order No.	1661630000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size
GTIN (EAN)	4008190418182	of cable entries: PG 29
Qty.	1 pc(s).	
Type	HDC 24B SBU 2PG21G	Version
Order No.	1661520000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard,
GTIN (EAN)	4008190418076	Size of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M25G	Version
Order No.	1786890000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size
GTIN (EAN)	4032248204137	of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 24B SBU 1M25G	Version
Order No.	1901150000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard,
GTIN (EAN)	4032248521258	Size of cable entries: M 25
Qty.	1 pc(s).	
Type	HDC 64D SBU 1M32G	Version
Order No.	1904350000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size
GTIN (EAN)	4032248585298	of cable entries: M 32
Qty.	1 pc(s).	
Type	HDC 64D SBU 2PG21G	Version
Order No.	1661590000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size
GTIN (EAN)	4008190418144	of cable entries: PG 21
Qty.	1 pc(s).	
Type	HDC 24B SBU 1PG21G	Version
Order No.	1661510000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, Standard,
GTIN (EAN)	4008190418069	Size of cable entries: PG 21
Qty.	1 pc(s).	

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	HDC 64D SBU 1M25G	Version
Order No.	1904340000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 25
GTIN (EAN)	4032248585601	
Qty.	1 pc(s).	
Type	HDC 64D SBU 2M32G	Version
Order No.	1786880000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Base housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204120	
Qty.	1 pc(s).	

Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B KBU 1PG21G	Version
Order No.	1661720000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 21
GTIN (EAN)	4008190418274	
Qty.	1 pc(s).	
Type	HDC 64D KBU 1PG29G	Version
Order No.	1661810000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: PG 29
GTIN (EAN)	4008190418359	
Qty.	1 pc(s).	
Type	HDC 64D KBU 1M32G	Version
Order No.	1786960000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, high, Size of cable entries: M 32
GTIN (EAN)	4032248204205	
Qty.	1 pc(s).	
Type	HDC 24B KBU 1PG29G	Version
Order No.	1661730000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 29
GTIN (EAN)	4008190418281	
Qty.	1 pc(s).	
Type	HDC 24B KBU 1M25G	Version
Order No.	1787920000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Coupling housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 25
GTIN (EAN)	4032248205363	
Qty.	1 pc(s).	

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Cover



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B DMDQ 2QB	Version
Order No.	1665640000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Cover for upper part of housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4008190422660	
Qty.	1 pc(s).	

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

Type	HDC 24B ABU	Version
Order No.	1212400000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Side-locking clamp not replaceable, Standard
GTIN (EAN)	4008190083939	
Qty.	1 pc(s).	

CH-HLAA-HLAB-24-0200-AG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Accessories

Type	HDC 24B ABU N	Version
Order No.	2488600000	HDC enclosures, Size: 8, Protection degree: IP65 (in plugged condition), Bulkhead housing, Side-locking clamp on lower side, Standard
GTIN (EAN)	4050118541533	
Qty.	1 pc(s).	

Size 8

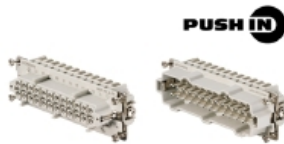

The PUSH IN connection is a direct-insert method of connection. The preprocessed wire can be inserted directly into the wire connection without the need for any tools.

Number of poles: **24**

Rated current: **16 A**

Rated voltage: **500 V**

Nominal voltage acc. to UL/CSA: **600 V AC/DC**

PUSH IN technology

General ordering data

Type	HDC HE 24 MP	Version
Order No.	1873590000	HDC insert, Male, 500 V, 16 A, Number of poles: 24, PUSH IN, Size: 8
GTIN (EAN)	4032248458202	
Qty.	1 pc(s).	
Type	HDC HE 24 FP	Version
Order No.	1873580000	HDC insert, Female, 500 V, 16 A, Number of poles: 24, PUSH IN, Size: 8
GTIN (EAN)	4032248458196	
Qty.	1 pc(s).	