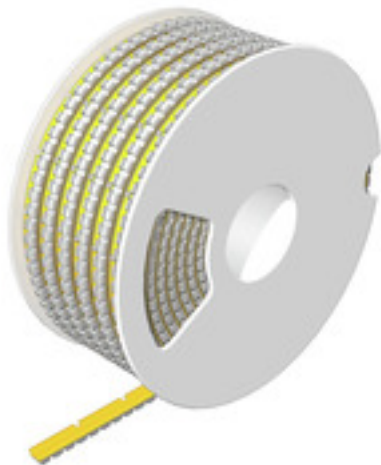


SFM 2/24 1.8-2.5 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

With the comprehensive MultiMark product family, you can achieve optimally structured and sustainable marking in every control cabinet. An example of this is our new SlimFix wire marker, which can be printed and snapped on particularly quickly. At the same time, they meet the highest requirements for vibration and shock resistance. The wire markers have an open design and can be easily and quickly installed before or after the wiring process.

General ordering data

Version	Conductor and cable markers, 1.8 - 2.5 mm, 24 x 4.6 mm, yellow
Order No.	2719140000
Type	SFM 2/24 1.8-2.5 MM GE
GTIN (EAN)	4050118888171
Qty.	700 pc(s).
compatible printer	2599430000

SFM 2/24 1.8-2.5 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Height	24 mm	Height (inches)	0.945 inch
Width	4.6 mm	Width (inches)	0.181 inch
Net weight	0.424 g		

General data

Colour	yellow	Halogen	No
Material	PC-ABS, TPU	Number per roll	700
Operating temperature range, max.	90 °C	Operating temperature range, min.	-50 °C
Size of labelling field	3.3 x 21.5 mm	Type of printing	neutral
UL 94 flammability rating	V-2	Version	with snap-in foot
Width	4.6 mm		

Conductor and cable markers

Conductor O.D.	1.8 - 2.5 mm	Conductor O.D., max.	2.5 mm
Conductor O.D., min.	1.8 mm	Conductor cross-section, max.	1.5 mm ²
Conductor cross-section, min.	0.75 mm ²	Cross-section for connected wire	0.75 - 1.5 mm ²
Halogen	No		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format

SFM 2/24 1.8-2.5 MM GE

Weidmüller Interface GmbH & Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Drawings

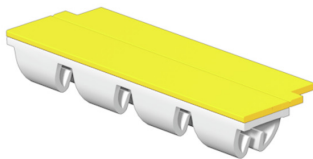

SFM 2/24 1.8-2.5 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	2005090000	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 pc(s).	

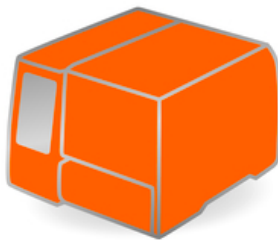THM MULTIMARK

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER SFM 2
Order No.	2786210000
GTIN (EAN)	4064675063230
Qty.	1 pc(s).