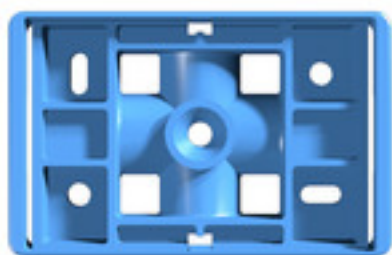


**CC-DT-H 85/54 BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

Version	ClipCard, Accessories, 90 x 58 mm, blue
Order No.	<a href="#">2737770000</a>
Type	CC-DT-H 85/54 BL
GTIN (EAN)	4064675211167
Qty.	20 pc(s).

**CC-DT-H 85/54 BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	13 mm	Depth (inches)	0.512 inch
Height	90 mm	Height (inches)	3.543 inch
Width	58 mm	Width (inches)	2.283 inch
Net weight	4.15 g		

**Temperatures**

Operating temperature range	-40...100 °C
-----------------------------	--------------

**General data**

Colour	blue	
Detectable in accordance with Rondotest	4.7 mm Al	
Halogen	No	
Material	Polyamide 66	
Number of markers per combination	1 MultiCard = Accessories	
Number of markers per packaging unit	Form of supply	MultiCard
Operating temperature range	-40... 100 °C	
Operating temperature range, max.	100 °C	
Operating temperature range, min.	-40 °C	
Recommended industries	Food processing industry	
UL 94 flammability rating	HB	
Width	58 mm	

**Device markers**

Halogen	No
---------	----

**Classifications**

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04
ECLASS 14.0	27-28-11-04		

**Environmental Product Compliance**

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

### CC-DT-H 85/54 BL

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

