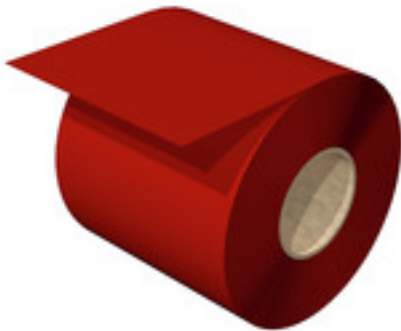


THM PV EL 90 RT 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

UV-radiation causes high stress and aging of plastic in the outdoor application.

Our new THM PV labels resist these influences and are extremely durable in outdoor use.

Compact designed packaging are our TABPACK-PV. These are pre-printed warning labels, which should be a part of the basic equipment of a professional photovoltaic builder.

Your advantages at a glance:

- Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours
- Individually labeled with the M-Print® PRO
- Easy and fast printing with the THM MultiMark

General ordering data

Version	Device markers, Device markers, 90 x , red
Order No.	2817430000
Type	THM PV EL 90 RT 30M
GTIN (EAN)	4064675322740
Qty.	1 pc(s).
compatible printer	2599430000 2599440000

THM PV EL 90 RT 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.1 mm	Depth (inches)	0.004 inch
Height	90 mm	Height (inches)	3.543 inch
Length	30,000 mm	Length (inches)	1,181.1 inch
Net weight	290 g		

General data

Adhesive	Polyacrylate adhesive	Approval acc. to UL 969	Yes
Colour	red	Halogen	Yes
Length	30,000 mm	Material	Vinyl film
Operating temperature range, max.	-50 °C	Operating temperature range, min.	110 °C
Printed characters	without	UL 94 flammability rating	V-0

Conductor and cable markers

Halogen	Yes
---------	-----

Device markers

Halogen	Yes
---------	-----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

Approvals

ROHS	Conform
------	---------

Downloads


White paper	Fact Sheet PV Markierer Fact Sheet EN PV Markers
Catalogues	Catalogues in PDF-format

THM PV EL 90 RT 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

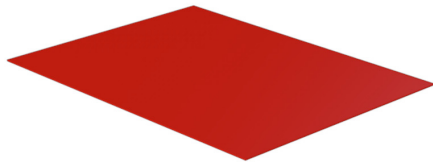

THM PV EL 90 RT 30M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

Ink ribbons

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 pc(s).	
Type	RIBBON MM 84/300 WS	Version
Order No.	2005040000	Ink ribbon
GTIN (EAN)	4050118390025	
Qty.	1 pc(s).	

THM PV EL 90 RT 30M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP ROLLER 115
Order No.	1357420000
GTIN (EAN)	4050118160314
Qty.	1 pc(s).