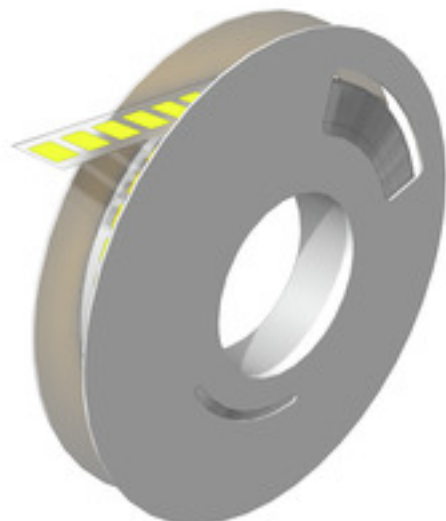


ESG-LP 9/15 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

Version	ESG, Device markers, 9 x 15 mm, yellow
Order No.	2835980000
Type	ESG-LP 9/15 MM GE
GTIN (EAN)	4064675427940
Qty.	15,000 pc(s).

ESG-LP 9/15 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	9 mm	Height (inches)	0.354 inch
Width	15 mm	Width (inches)	0.591 inch
Net weight	0.026 g		

General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	yellow	Halogen	No
Material	Polyamide	Operating temperature range, max.	150 °C
Operating temperature range, min.	-40 °C	Printed characters	without
UL 94 flammability rating	V-0	Version	Self-adhesive, halogen-free
Width	15 mm		

Device markers

Halogen	No
---------	----

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ETIM 9.0	EC001288
ECLASS 9.0	27-40-06-29	ECLASS 9.1	27-40-06-29
ECLASS 10.0	27-40-06-29	ECLASS 11.0	27-28-11-04
ECLASS 12.0	27-28-11-04	ECLASS 13.0	27-28-11-04

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format

ESG-LP 9/15 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

