

THM MULTIMARK LPC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

THM MultiMark LPC (Labeling Processing Center)

- Fast and efficient marking of devices and operating equipment
- Laser assisted alignment
- Ergonomic operation via foot switch
- High repetition accuracy
- Controlled via Weidmüller M-Print PRO© software

General ordering data

Version	Marking systems, Thermal transfer, 300 DPI, Multi-Mark, Labels, Label reel
Order No.	2878190000
Type	THM MULTIMARK LPC
GTIN (EAN)	4064675667568
Qty.	1 pc(s).

THM MULTIMARK LPC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	648 mm	Depth (inches)	25.512 inch
Height	785 mm	Height (inches)	30.905 inch
Width	466 mm	Width (inches)	18.346 inch
Net weight	22,000 g		

Labelling systems

Included in delivery	USB cable, Euro plug, UK plug, US plug, Manual, RIBBON MM-TB 25/360 SW ink ribbon, DVD with M-Print® PRO, Ink ribbon core, Print roller, Applicator incl. laser unit and stamp, Mounting foot, Footswitch, Printer	Interface	USB 2.0, Ethernet, Wi-Fi
Marker type	MultiMark, Labels, Label reel	Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10
Operation with rechargeable batteries	No	Print resolution, max.	300 DPI
Printing method	Thermal transfer	Printing speed	125 mm/s
Software	M-Print® PRO	System requirements	PC with operating system Windows 7, 8 or 10
Voltage supply	100...240 V AC		

Classifications

ETIM 6.0	EC000610	ETIM 7.0	EC000610
ETIM 8.0	EC000610	ETIM 9.0	EC000610
ECLASS 9.0	24-32-11-90	ECLASS 9.1	24-32-11-02
ECLASS 10.0	24-32-11-90	ECLASS 11.0	24-32-11-90
ECLASS 12.0	24-32-11-90	ECLASS 13.0	24-32-11-90
ECLASS 14.0	24-32-11-90		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant

Downloads

Approval/Certificate/Document of Conformity	Declaration of Conformity
User Documentation	Manual THM MultiMark LPC - DE Manual THM MultiMark LPC - EN Manual THM MultiMark LPC - ES Manual THM MultiMark LPC - IT Manual THM MultiMark LPC - NL Manual THM MultiMark LPC - FR
Catalogues	Catalogues in PDF-format

THM MULTIMARK LPC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

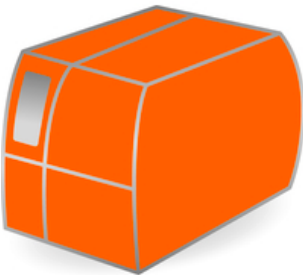
Germany

www.weidmueller.com**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	2005090000	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 pc(s).	

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110
Order No.	2672590000
GTIN (EAN)	4050118708097
Qty.	1 pc(s).