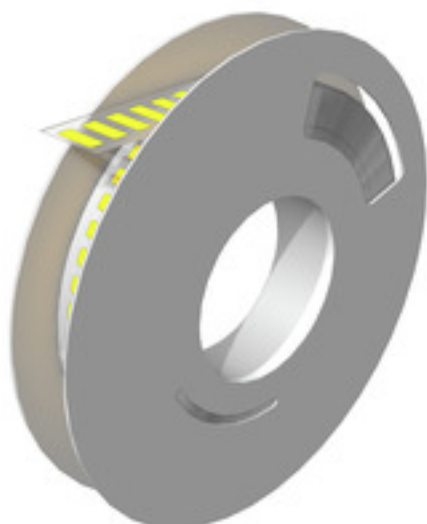


ESG-LP 6/17 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

| | |
|------------|--|
| Version | ESG, Device markers, 6 x 17 mm, yellow |
| Order No. | 2885790000 |
| Type | ESG-LP 6/17 MM GE |
| GTIN (EAN) | 4064675854395 |
| Qty. | 24,000 pc(s). |

ESG-LP 6/17 MM GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

| | | | |
|------------|---------|-----------------|------------|
| Depth | 0.05 mm | Depth (inches) | 0.002 inch |
| Height | 6 mm | Height (inches) | 0.236 inch |
| Width | 17 mm | Width (inches) | 0.669 inch |
| Net weight | 0.014 g | | |

General data

| | | | |
|-----------------------------------|-------------------|-----------------------------------|-----------------------------|
| Adhesive | Acrylate adhesive | Approval acc. to UL 969 | Yes |
| Colour | yellow | Halogen | No |
| Material | Polyamide | Operating temperature range, max. | 150 °C |
| Operating temperature range, min. | -40 °C | Printed characters | without |
| UL 94 flammability rating | V-0 | Version | Self-adhesive, halogen-free |
| Width | 17 mm | | |

Device markers

| | |
|---------|----|
| Halogen | No |
|---------|----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001288 | ETIM 7.0 | EC001288 |
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ECLASS 9.0 | 27-40-06-29 | ECLASS 9.1 | 27-40-06-29 |
| ECLASS 10.0 | 27-40-06-29 | ECLASS 11.0 | 27-28-11-04 |
| ECLASS 12.0 | 27-28-11-04 | ECLASS 13.0 | 27-28-11-04 |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|------------------|--|
| Engineering Data | CAD data – STEP |
| Catalogues | Catalogues in PDF-format |

ESG-LP 6/17 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

