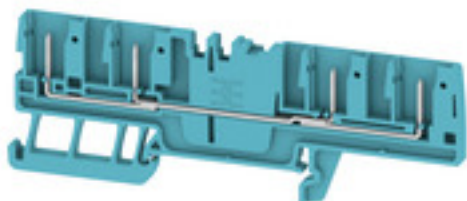


**APGTB 1.5 FT 4C/4 BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Some applications demand for a pluggable, modular solution to be more flexible or to facilitate the installation. Where complete functional units have to be prefabricated or replaced, modular and flexible connection systems are required. Our pluggable terminal blocks can be quickly assembled and are completely factory tested.

**General ordering data**

Version	Plug-in modular terminals, blue
Order No.	<a href="#">2898130000</a>
Type	APGTB 1.5 FT 4C/4 BL
GTIN (EAN)	4064675903222
Qty.	100 pc(s).

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	33.5 mm	Depth (inches)	1.319 inch
Height	80 mm	Height (inches)	3.15 inch
Width	3.5 mm	Width (inches)	0.138 inch
Net weight	6.2 g		

## Temperatures

Continuous operating temp., min.	-60 °C	Continuous operating temp., max.	130 °C
----------------------------------	--------	----------------------------------	--------

## Material data

Material	Wemid	Colour	blue
UL 94 flammability rating	V-0		

## System specifications

End cover plate required	Yes	Number of levels	1
N-function	No	PE function	No
PEN function	No		

## Additional technical data

Open sides	right	Type of fixing	TS 35
Type of mounting	TS 35		

## Conductors for clamping (rated connection)

Connection direction	top	Number of connections	4
----------------------	-----	-----------------------	---

## PE rating data

PEN function	No
--------------	----

## Rating data

Rated DC voltage	500 V	Current at maximum wires	17.5 A
Volume resistance according to IEC 60947-7-x	1.83 mΩ	Rated impulse withstand voltage	6 kV
Power loss in accordance with IEC 60947-7-x	0.56 W	Pollution severity	3
Surge voltage category	III		

## UL rating data

Certificate No. (cURus)	E60693	Conductor size Factory wiring max. (cURus)	14 AWG
Conductor size Factory wiring min. (cURus)	26 AWG	Conductor size Field wiring max. (cURus)	14 AWG
Conductor size Field wiring min. (cURus)	26 AWG	Current size B (cURus)	13 A
Current size C (cURus)	13 A	Current size D (cURus)	5 A
Voltage size B (cURus)	300 V	Voltage size C (cURus)	300 V
Voltage size D (cURus)	600 V		

## APGTB 1.5 FT 4C/4 BL

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

## Classifications

ETIM 7.0	EC000897	ETIM 8.0	EC000897
ETIM 9.0	EC000897	ECLASS 11.0	27-14-11-20
ECLASS 12.0	27-14-11-20	ECLASS 13.0	27-25-01-17

## Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (cURus)	E60693

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">CE Declaration of Conformity</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

### APGTB 1.5 FT 4C/4 BL

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings



## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Protective covers



The cover of the plug contact offers protection from external influences, e.g. soiling from dust.

## General ordering data

Type	APGPC 1.5	Version
Order No.	<a href="#">2482530000</a>	Terminal cover, Wemid, orange, Height: 16 mm, Width: 3.3 mm,
GTIN (EAN)	4050118494563	Depth: 13 mm
Qty.	50 pc(s).	

1.5 mm<sup>2</sup>


The plug-in cross-connections feature easy handling and quick installation. This saves a great deal of time during installation in comparison with screwed solutions.

## General ordering data

Type	ZQV 1.5N/5 BL	Version
Order No.	<a href="#">1985590000</a>	Cross-connector (terminal), Plugged, Number of poles: 5, Pitch in mm
GTIN (EAN)	4050118370430	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/20	Version
Order No.	<a href="#">1985600000</a>	Cross-connector (terminal), Plugged, Number of poles: 20, Pitch in mm
GTIN (EAN)	4050118370225	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/4 RD	Version
Order No.	<a href="#">1985690000</a>	Cross-connector (terminal), Plugged, Number of poles: 4, Pitch in mm
GTIN (EAN)	4050118370515	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	60 pc(s).	
Type	ZQV 1.5N/3 BL	Version
Order No.	<a href="#">1985550000</a>	Cross-connector (terminal), Plugged, Number of poles: 3, Pitch in mm
GTIN (EAN)	4050118370485	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	60 pc(s).	
Type	ZQV 1.5N/4 BL	Version
Order No.	<a href="#">1985570000</a>	Cross-connector (terminal), Plugged, Number of poles: 4, Pitch in mm
GTIN (EAN)	4050118370317	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	60 pc(s).	

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	ZQV 1.5N/50 BL	Version
Order No.	<a href="#">1985720000</a>	Cross-connector (terminal), Plugged, Number of poles: 50, Pitch in mm
GTIN (EAN)	4050118370546	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	5 pc(s).	
Type	ZQV 1.5N/8 RD	Version
Order No.	<a href="#">1985770000</a>	Cross-connector (terminal), Plugged, Number of poles: 8, Pitch in mm
GTIN (EAN)	4050118370508	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/10 BL	Version
Order No.	<a href="#">1985680000</a>	Cross-connector (terminal), Plugged, Number of poles: 10, Pitch in mm
GTIN (EAN)	4050118370539	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/8 BL	Version
Order No.	<a href="#">1985640000</a>	Cross-connector (terminal), Plugged, Number of poles: 8, Pitch in mm
GTIN (EAN)	4050118370461	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/2 RD	Version
Order No.	<a href="#">1985650000</a>	Cross-connector (terminal), Plugged, Number of poles: 2, Pitch in mm
GTIN (EAN)	4050118370324	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	60 pc(s).	
Type	ZQV 1.5N/50 RD	Version
Order No.	<a href="#">1985820000</a>	Cross-connector (terminal), Plugged, Number of poles: 50, Pitch in mm
GTIN (EAN)	4050118370270	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	5 pc(s).	
Type	ZQV 1.5N/3	Version
Order No.	<a href="#">1985480000</a>	Cross-connector (terminal), Plugged, Number of poles: 3, Pitch in mm
GTIN (EAN)	4050118370096	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	60 pc(s).	
Type	ZQV 1.5N/5 RD	Version
Order No.	<a href="#">1985710000</a>	Cross-connector (terminal), Plugged, Number of poles: 5, Pitch in mm
GTIN (EAN)	4050118370256	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/20 RD	Version
Order No.	<a href="#">1985810000</a>	Cross-connector (terminal), Plugged, Number of poles: 20, Pitch in mm
GTIN (EAN)	4050118370355	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/6	Version
Order No.	<a href="#">1985510000</a>	Cross-connector (terminal), Plugged, Number of poles: 6, Pitch in mm
GTIN (EAN)	4050118370188	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/8	Version
Order No.	<a href="#">1985540000</a>	Cross-connector (terminal), Plugged, Number of poles: 8, Pitch in mm
GTIN (EAN)	4050118370218	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/9 RD	Version
Order No.	<a href="#">1985790000</a>	Cross-connector (terminal), Plugged, Number of poles: 9, Pitch in mm
GTIN (EAN)	4050118370386	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/5	Version
Order No.	<a href="#">1985500000</a>	Cross-connector (terminal), Plugged, Number of poles: 5, Pitch in mm
GTIN (EAN)	4050118369991	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	

Creation date May 23, 2024 7:15:40 AM CEST

Catalogue status 18.05.2024 / We reserve the right to make technical changes.

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	ZQV 1.5N/10 RD	Version
Order No.	<a href="#">1985800000</a>	Cross-connector (terminal), Plugged, Number of poles: 10, Pitch in mm
GTIN (EAN)	4050118370393	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/2	Version
Order No.	<a href="#">1985410000</a>	Cross-connector (terminal), Plugged, Number of poles: 2, Pitch in mm
GTIN (EAN)	4050118369861	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	60 pc(s).	
Type	ZQV 1.5N/9	Version
Order No.	<a href="#">1985560000</a>	Cross-connector (terminal), Plugged, Number of poles: 9, Pitch in mm
GTIN (EAN)	4050118370409	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/7	Version
Order No.	<a href="#">1985520000</a>	Cross-connector (terminal), Plugged, Number of poles: 7, Pitch in mm
GTIN (EAN)	4050118370195	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/20 BL	Version
Order No.	<a href="#">1985700000</a>	Cross-connector (terminal), Plugged, Number of poles: 20, Pitch in mm
GTIN (EAN)	4050118370331	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/10	Version
Order No.	<a href="#">1985580000</a>	Cross-connector (terminal), Plugged, Number of poles: 10, Pitch in mm
GTIN (EAN)	4050118370416	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	20 pc(s).	
Type	ZQV 1.5N/50	Version
Order No.	<a href="#">1985620000</a>	Cross-connector (terminal), Plugged, Number of poles: 50, Pitch in mm
GTIN (EAN)	4050118370300	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	5 pc(s).	
Type	ZQV 1.5N/6 RD	Version
Order No.	<a href="#">1985730000</a>	Cross-connector (terminal), Plugged, Number of poles: 6, Pitch in mm
GTIN (EAN)	4050118370454	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/6 BL	Version
Order No.	<a href="#">1985610000</a>	Cross-connector (terminal), Plugged, Number of poles: 6, Pitch in mm
GTIN (EAN)	4050118370492	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/7 RD	Version
Order No.	<a href="#">1985750000</a>	Cross-connector (terminal), Plugged, Number of poles: 7, Pitch in mm
GTIN (EAN)	4050118370249	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	20 pc(s).	
Type	ZQV 1.5N/2 BL	Version
Order No.	<a href="#">1985530000</a>	Cross-connector (terminal), Plugged, Number of poles: 2, Pitch in mm
GTIN (EAN)	4050118370423	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	60 pc(s).	
Type	ZQV 1.5N/4	Version
Order No.	<a href="#">1985490000</a>	Cross-connector (terminal), Plugged, Number of poles: 4, Pitch in mm
GTIN (EAN)	4050118370201	(P): 3.50, Insulated: Yes, 17.5 A, orange
Qty.	60 pc(s).	
Type	ZQV 1.5N/3 RD	Version
Order No.	<a href="#">1985670000</a>	Cross-connector (terminal), Plugged, Number of poles: 3, Pitch in mm
GTIN (EAN)	4050118370348	(P): 3.50, Insulated: Yes, 17.5 A, red
Qty.	60 pc(s).	

Creation date May 23, 2024 7:15:40 AM CEST

Catalogue status 18.05.2024 / We reserve the right to make technical changes.

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	ZQV 1.5N/9 BL	Version
Order No.	<a href="#">1985660000</a>	Cross-connector (terminal), Plugged, Number of poles: 9, Pitch in mm
GTIN (EAN)	4050118370478	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	
Type	ZQV 1.5N/7 BL	Version
Order No.	<a href="#">1985630000</a>	Cross-connector (terminal), Plugged, Number of poles: 7, Pitch in mm
GTIN (EAN)	4050118370522	(P): 3.50, Insulated: Yes, 17.5 A, blue
Qty.	20 pc(s).	

1.5 mm<sup>2</sup>


The plugs for our WeiCoS-System are available for all different connection systems. The product range includes preassembled connectors from 1 to 10 poles and the possibility of an individual assembly. This ensures maximum flexibility for every application. The customized accessories increase the safety and protection against environmental influences.

## General ordering data

Type	APG 1.5 R GN	Version
Order No.	<a href="#">2482330000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, green
GTIN (EAN)	4050118494396	
Qty.	50 pc(s).	
Type	APG 1.5/3	Version
Order No.	<a href="#">2482360000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 3, dark beige
GTIN (EAN)	4050118494426	
Qty.	25 pc(s).	
Type	APG 1.5/4-3BG-GN	Version
Order No.	<a href="#">2482450000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 4, dark beige, green
GTIN (EAN)	4050118494518	
Qty.	25 pc(s).	
Type	APG 1.5/8	Version
Order No.	<a href="#">2482410000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 8, dark beige
GTIN (EAN)	4050118494471	
Qty.	20 pc(s).	
Type	APG 1.5/4-3BG-GN	Version
Order No.	<a href="#">2719750000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, dark beige, green
GTIN (EAN)		
Qty.	25 pc(s).	
Type	APG 1.5 L BL	Version
Order No.	<a href="#">2482260000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, blue
GTIN (EAN)	4050118494297	
Qty.	50 pc(s).	
Type	APG 1.5/3-BG-BL-GN	Version
Order No.	<a href="#">2482460000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 3, dark beige, blue, green
GTIN (EAN)	4050118494525	
Qty.	25 pc(s).	



## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	APG 1.5/7	Version
Order No.	<a href="#">2482400000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 7, dark beige
GTIN (EAN)	4050118494464	
Qty.	25 pc(s).	
Type	APG 1.5/7-6BG-GN	Version
Order No.	<a href="#">2719800000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 7, dark beige, green
GTIN (EAN)	4050118811285	
Qty.	25 pc(s).	
Type	APG 1.5/10	Version
Order No.	<a href="#">2482430000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 10, dark beige
GTIN (EAN)	4050118494495	
Qty.	20 pc(s).	
Type	APG 1.5/9-8BG-GN	Version
Order No.	<a href="#">2719820000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 9, dark beige, green
GTIN (EAN)	4050118811407	
Qty.	20 pc(s).	
Type	APG 1.5/1	Version
Order No.	<a href="#">2482340000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 1, dark beige
GTIN (EAN)	4050118494402	
Qty.	50 pc(s).	
Type	APG 1.5/5-4BG-GN	Version
Order No.	<a href="#">2719770000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 5, dark beige, green
GTIN (EAN)	4050118811421	
Qty.	25 pc(s).	
Type	APG 1.5/3-2BG-GN	Version
Order No.	<a href="#">2719740000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 3, dark beige, green
GTIN (EAN)	4050118811438	
Qty.	25 pc(s).	
Type	APG 1.5/6-5BG-GN	Version
Order No.	<a href="#">2719780000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 6, dark beige, green
GTIN (EAN)	4050118811414	
Qty.	25 pc(s).	
Type	APG 1.5 MI BL	Version
Order No.	<a href="#">2482290000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 1, blue
GTIN (EAN)	4050118494327	
Qty.	50 pc(s).	
Type	APG 1.5/4	Version
Order No.	<a href="#">2482370000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 4, dark beige
GTIN (EAN)	4050118494433	
Qty.	25 pc(s).	
Type	APG 1.5/5	Version
Order No.	<a href="#">2482380000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 5, dark beige
GTIN (EAN)	4050118494440	
Qty.	25 pc(s).	
Type	APG 1.5 MI	Version
Order No.	<a href="#">2482280000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 1, dark beige
GTIN (EAN)	4050118494310	
Qty.	50 pc(s).	
Type	APG 1.5/8-7BG-GN	Version
Order No.	<a href="#">2719810000</a>	Plug, 1.5 mm², 500 V, 17.5 A, Number of poles: 8, dark beige, green
GTIN (EAN)	4050118811179	
Qty.	20 pc(s).	

Creation date May 23, 2024 7:15:40 AM CEST

Catalogue status 18.05.2024 / We reserve the right to make technical changes.

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

Type	APG 1.5/5-3BG-BL-GN	Version
Order No.	<a href="#">2482440000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 5, dark beige, blue,
GTIN (EAN)	4050118494501	green
Qty.	25 pc(s).	
Type	APG 1.5/6	Version
Order No.	<a href="#">2482390000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 6, dark beige
GTIN (EAN)	4050118494457	
Qty.	25 pc(s).	
Type	APG 1.5 R	Version
Order No.	<a href="#">2482310000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, dark beige
GTIN (EAN)	4050118494372	
Qty.	50 pc(s).	
Type	APG 1.5/10-9BG-GN	Version
Order No.	<a href="#">2719830000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 10, dark beige, green
GTIN (EAN)	4050118811292	
Qty.	20 pc(s).	
Type	APG 1.5 L	Version
Order No.	<a href="#">2482250000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, dark beige
GTIN (EAN)	4050118494280	
Qty.	50 pc(s).	
Type	APG 1.5 R BL	Version
Order No.	<a href="#">2482320000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, blue
GTIN (EAN)	4050118494389	
Qty.	50 pc(s).	
Type	APG 1.5 L GN	Version
Order No.	<a href="#">2482270000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, green
GTIN (EAN)	4050118494303	
Qty.	50 pc(s).	
Type	APG 1.5/2	Version
Order No.	<a href="#">2482350000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, dark beige
GTIN (EAN)	4050118494419	
Qty.	25 pc(s).	
Type	APG 1.5/9	Version
Order No.	<a href="#">2482420000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 9, dark beige
GTIN (EAN)	4050118494488	
Qty.	20 pc(s).	
Type	APG 1.5 MI GN	Version
Order No.	<a href="#">2482300000</a>	Plug, 1.5 mm <sup>2</sup> , 500 V, 17.5 A, Number of poles: 1, green
GTIN (EAN)	4050118494365	
Qty.	50 pc(s).	

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	DEK 5/3.5 MC NE GE	Version
Order No.	<a href="#">1369480000</a>	Dekafix, Terminal marker, 5 x 3.5 mm, Pitch in mm (P): 3.50
GTIN (EAN)	4050118171860	Weidmueller, yellow
Qty.	500 pc(s).	
Type	DEK 5/3.5 MC NE WS	Version
Order No.	<a href="#">1755270000</a>	Dekafix, Terminal marker, 5 x 3.5 mm, Pitch in mm (P): 3.50
GTIN (EAN)	4032248017348	Weidmueller, white
Qty.	500 pc(s).	
Type	DEK 5/3.5 PLUS MC NE WS	Version
Order No.	<a href="#">2003750000</a>	Dekafix, Terminal marker, 5 x 3.5 mm, Pitch in mm (P): 3.50
GTIN (EAN)	4050118424430	Weidmueller, white
Qty.	1,600 pc(s).	

## A-Series



Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

Type	AEB 35 SCL/1 V0 BK	Version
Order No.	<a href="#">2661300000</a>	A-series, End bracket
GTIN (EAN)	4050118702187	
Qty.	20 pc(s).	

**APGTB 1.5 FT 4C/4 BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories**

Type	AEB 35 SCL/1 V0	Version
Order No.	<a href="#">2661280000</a>	A-series, End bracket
GTIN (EAN)	4050118702163	
Qty.	20 pc(s).	

**Locking elements**

The plugs can be securely and easily fixed to the base terminal by using a locking element. The locking element avoids an unintentional disconnection of the plugs from the base terminal and ensures maximum safety.

**General ordering data**

Type	APGLE 1.5	Version
Order No.	<a href="#">2482720000</a>	Locking clips (terminal), Wemid, orange
GTIN (EAN)	4050118496253	
Qty.	25 pc(s).	

**1.5 mm<sup>2</sup>**

1.5  
mm<sup>2</sup>

End plates are fitted to the open side of the last modular terminal before the end bracket. The use of an end plate ensures the function of the modular terminal and the specified rated voltage. It guarantees protection against contact with live parts and makes the final terminal finger-proof.

**General ordering data**

Type	AEP PGTB 1.5 4C/4	Version
Order No.	<a href="#">2898180000</a>	A-series, End plate
GTIN (EAN)	4064675903277	
Qty.	20 pc(s).	

## APGTB 1.5 FT 4C/4 BL

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Coding elements



Through the use of coding pins, individual coding options ensure trouble-free plug-in connection.

## General ordering data

Type	APGCE	Version
Order No.	<a href="#">1514490000</a>	Coding element (terminal), Wemid, orange, Width: 3.3 mm
GTIN (EAN)	4050118321906	
Qty.	50 pc(s).	

## Custom printing



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
- Strips for fast installation
- Terminal markers, suitable for all Weidmüller cable connectors
- Available as blank MultiCard or with standard printing

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	DEK 5/3.5 PLUS MC SDR	Version
Order No.	<a href="#">2007790000</a>	Dekafix, Terminal marker, 5 x 3.5 mm, Pitch in mm (P): 3.50
GTIN (EAN)	4050118393347	Weidmueller, To customer specification
Qty.	320 pc(s).	


Type	DEK 5/3.5 MC SDR	Version
Order No.	<a href="#">1767730000</a>	Dekafix, Terminal marker, 5 x 3.5 mm, Pitch in mm (P): 3.50
GTIN (EAN)	4032248102532	Weidmueller, To customer specification
Qty.	100 pc(s).	

**APGTB 1.5 FT 4C/4 BL****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

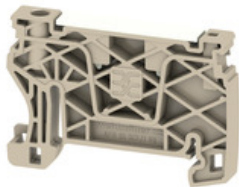[www.weidmueller.com](http://www.weidmueller.com)**Accessories****End brackets****General ordering data**

Type	AEB 35 SCL/1 V0 BK DL	Version
Order No.	<a href="#">2570250000</a>	A-series, End bracket
GTIN (EAN)	4050118580266	
Qty.	50 pc(s).	

**Strain reliefs**

The strain relief protects the contact against mechanical stress and protects the connector against inadvertent release from the contact point.

**General ordering data**

Type	APGSR 1.5 - 4P	Version
Order No.	<a href="#">2482740000</a>	Strain relief (terminal), Wemid, orange
GTIN (EAN)	4050118494204	
Qty.	25 pc(s).	
Type	APGSR 1.5	Version
Order No.	<a href="#">2482730000</a>	Strain relief (terminal), Wemid, orange
GTIN (EAN)	4050118493993	
Qty.	25 pc(s).	
Type	APGSR 1.5 - 8P	Version
Order No.	<a href="#">2482750000</a>	Strain relief (terminal), Wemid, orange
GTIN (EAN)	4050118494211	
Qty.	25 pc(s).	