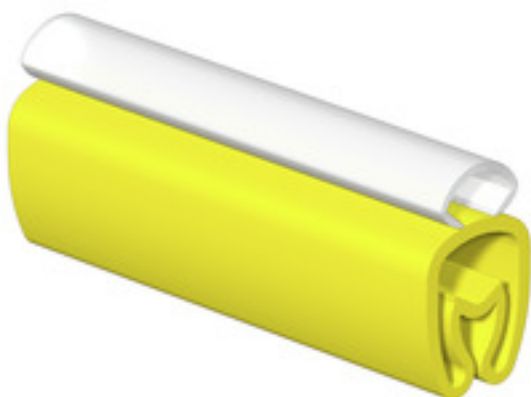


**VT-TM 2/30 HF-V0****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**General ordering data**

Version	, Socket x 5.3 mm, TPU, Colour: yellow, Transparent, Conductor O.D.: 4 - 10 mm
Order No.	<a href="#">2902810000</a>
Type	VT-TM 2/30 HF-V0
GTIN (EAN)	4099986005365
Qty.	100 pc(s).

**VT-TM 2/30 HF-V0****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Height	30 mm	Height (inches)	1.181 inch
Width	5.3 mm	Width (inches)	0.209 inch
Net weight	3 g		

**Temperatures**

Operating temperature range	-30...90 °C
-----------------------------	-------------

**General data**

Colour	yellow, Transparent	Halogen	No
Material	TPU	Operating temperature range	-30...90 °C
Operating temperature range, max.	90 °C	Operating temperature range, min.	-30 °C
Printed characters	without	Recommended industries	Transportation, Machinery
Type of printing	neutral	UL 94 flammability rating	V-0
Width	5.3 mm		

**Conductor and cable markers**

Conductor O.D.	4 - 10 mm	Conductor O.D., max.	10 mm
Conductor O.D., min.	4 mm	Conductor cross-section, max.	2.5 mm <sup>2</sup>
Conductor cross-section, min.	0.75 mm <sup>2</sup>	Cross-section for connected wire	0.75 - 2.5 mm <sup>2</sup>
Halogen	No		

**Classifications**

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ETIM 9.0	EC001530
ECLASS 9.0	27-40-04-01	ECLASS 9.1	27-40-04-01
ECLASS 10.0	27-40-04-01	ECLASS 11.0	27-28-11-02
ECLASS 12.0	27-28-11-02	ECLASS 13.0	27-28-11-02

**Environmental Product Compliance**

REACH SVHC	/
------------	---

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

**VT-TM 2/30 HF-V0****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****TM-I 30****Process reliability: TM-I**

TM-I inlay tags have a guide tab which allows them to slide easily into the transparent sleeves from the type TM. Once the tag is in place, the tab is snapped off at the predetermined break point. The ready-assembled sleeves can then be simply pushed over the conductors. Your benefits: large quantities can be efficiently pre-assembled in a single step.

**General ordering data**

Type	TM-I 30 MM WS	Version
Order No.	<a href="#">2005530000</a>	TM-I, Insert markers, 30 x 4 mm, white
GTIN (EAN)	4050118390070	
Qty.	2,000 pc(s).	
Type	TM-I 30 MM BL	Version
Order No.	<a href="#">2005990000</a>	TM-I, Insert markers, 30 x 4 mm, blue
GTIN (EAN)	4050118390452	
Qty.	2,000 pc(s).	
Type	TM-I 30 MM RT	Version
Order No.	<a href="#">2005870000</a>	TM-I, Insert markers, 30 x 4 mm, red
GTIN (EAN)	4050118390384	
Qty.	2,000 pc(s).	
Type	TM-I 30 MM GE	Version
Order No.	<a href="#">2005700000</a>	TM-I, Insert markers, 30 x 4 mm, yellow
GTIN (EAN)	4050118390339	
Qty.	2,000 pc(s).	

## VT-TM 2/30 HF-V0

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Blank



TM-I is an acknowledged and accredited marker type for traffic engineering applications. There are various different tag lengths available for individual labelling with long character strings. Easy handling of separation and installation thanks to the project marker field. Pre-attachment of sleeves and retrofitting of tags offer excellent versatility

The special contour of TM-I allows easy assembly and secures firm positioning. They are compatible with a number of commercially available sleeves. Thanks to the MultiCard format, the tags can be printed quickly and conveniently with the PrintJet CONNECT, plotter or the STI pen.

- Easy handling of separation and installation thanks to the project marker field.
- Acknowledged and accredited marker for traffic engineering applications
- Pre-attachment of sleeves and retrofitting of tags offer excellent versatility
- Not suited for labelling with P-Ink or STI pen in connection with CLI T sleeves

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	TM-I 30 MC NE GE	Version
Order No.	<a href="#">1876370000</a>	TM-I, Insert markers, 30 x 4 mm, yellow
GTIN (EAN)	4032248466443	
Qty.	300 pc(s).	
Type	TM-I 30 MC NE RT	Version
Order No.	<a href="#">1876380000</a>	TM-I, Insert markers, 30 x 4 mm, red
GTIN (EAN)	4032248466474	
Qty.	300 pc(s).	
Type	TM-I 30 MC NE GN	Version
Order No.	<a href="#">1365610000</a>	TM-I, Insert markers, 30 x 4 mm, green
GTIN (EAN)	4050118171907	
Qty.	300 pc(s).	
Type	TM-I 30 MC NE WS	Version
Order No.	<a href="#">1876390000</a>	TM-I, Insert markers, 30 x 4 mm, white
GTIN (EAN)	4032248466450	
Qty.	300 pc(s).	
Type	TM-I 30 MC NE BL	Version
Order No.	<a href="#">1876400000</a>	TM-I, Insert markers, 30 x 4 mm, blue
GTIN (EAN)	4032248466467	
Qty.	300 pc(s).	