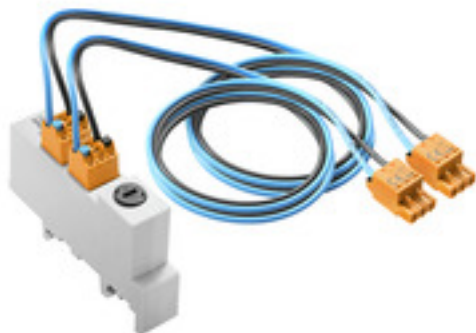


V-ZPA FUSE HOLDER**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**General ordering data**

Version	
Order No.	2904480000
Type	V-ZPA FUSE HOLDER
GTIN (EAN)	4099986010383
Qty.	1 pc(s).

V-ZPA FUSE HOLDER

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	65.5 mm	Depth (inches)	2.579 inch
Height	95.2 mm	Height (inches)	3.748 inch
Width	18.5 mm	Width (inches)	0.728 inch
Net weight	144 g		

Temperatures

Operating temperature	-25 °C...55 °C	Humidity	5 - 95% rel. humidity
-----------------------	----------------	----------	-----------------------

General data

Colour	grey	Operating altitude	≤ 4000 m
Protection degree	IP00	Rail	Busbar

Insulation coordination acc. to EN 50178

Pollution severity	2
--------------------	---

Rated data IEC / EN

Fuse	6.3 A	Rated voltage (AC)	240 V
Short-circuit current rating I_{SCCR}	25 kA	Voltage type	AC

Connection data

Wire connection method	PUSH IN	Wire cross-section, solid, max.	2.5 mm ²
------------------------	---------	---------------------------------	---------------------

Classifications

ETIM 6.0	EC000941	ETIM 7.0	EC000941
ETIM 8.0	EC000941	ETIM 9.0	EC000941
ECLASS 9.0	27-13-08-05	ECLASS 9.1	27-13-08-05
ECLASS 10.0	27-13-08-05	ECLASS 11.0	27-13-08-05
ECLASS 12.0	27-17-90-90	ECLASS 13.0	27-17-90-90

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	EU Konformitätserklärung / EU Declaration of Conformity
Engineering Data	CAD data – STEP
User Documentation	Beipackzettel / Instruction sheet
Catalogues	Catalogues in PDF-format

V-ZPA FUSE HOLDER

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

