

THM MULTIMARK TWIN**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Version	Marking systems, Thermotransfer, 300 DPI, Shrink-fit sleeves
Order No.	2931860000
Type	THM MULTIMARK TWIN
GTIN (EAN)	4099986669895
Qty.	1 pc(s).

THM MULTIMARK TWIN

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	395 mm	Depth (inches)	15.551 inch
Height	544 mm	Height (inches)	21.417 inch
Width	248 mm	Width (inches)	9.764 inch
Net weight	21,000 g		

Labelling systems

Interface	LAN, USB 2.0	Marker type	Shrink-fit sleeves
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10, Windows 11	Print resolution, max.	300 DPI
Printing method	Thermotransfer	Printing speed	150 mm/s
Software	M-Print® PRO	Type	THM TwinMark printer
Voltage supply	100...240 V AC		

Classifications

ETIM 6.0	EC000610	ETIM 7.0	EC000610
ETIM 8.0	EC000610	ETIM 9.0	EC000610
ECLASS 9.0	24-32-11-90	ECLASS 9.1	24-32-11-02
ECLASS 10.0	24-32-11-90	ECLASS 11.0	24-32-11-90
ECLASS 12.0	24-32-11-90	ECLASS 13.0	24-32-11-90

Downloads

Approval/Certificate/Document of Conformity	CE Declaration of conformity UKCA Declaration of conformity
User Documentation	Manual THM MultiMark TWIN - DE Manual THM MultiMark TWIN - EN Manual THM MultiMark TWIN - IT Manual THM MultiMark TWIN - NL Manual THM MultiMark TWIN - FR Manual THM MultiMark TWIN - ES
Catalogues	Catalogues in PDF-format

THM MULTIMARK TWIN

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-HS 60/300 SW	Version
Order No.	2448880000	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 pc(s).	
Type	RIBBON HSS HF EL 40/300 ...	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 pc(s).	

THM MULTIMARK PLUS

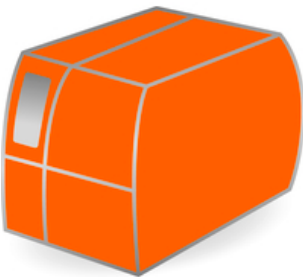

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MM PLUS ROLLER 110	
Order No.	2672590000	
GTIN (EAN)	4050118708097	
Qty.	1 pc(s).	
Type	THM PLUS M PERFORATOR	Version
Order No.	1540770000	Cutting kit
GTIN (EAN)	4050118345711	
Qty.	1 pc(s).	