

RSS112060**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

Individual relays for TERMSERIES

- Electromechanical relays
- Different contact materials

General ordering data

Version	TERMSERIES, Relay, Number of contacts: 1, CO contact AgNi gold-plated, Rated control voltage: 60 V DC, Continuous current: 6 A, Plug-in connection, Test button available: No
Order No.	4061600000
Type	RSS112060
GTIN (EAN)	4032248252299
Qty.	20 pc(s).

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	15 mm	Depth (inches)	0.591 inch
Height	28 mm	Height (inches)	1.102 inch
Width	5 mm	Width (inches)	0.197 inch
Net weight	4.56 g		

Temperatures

Storage temperature	-40 °C...85 °C	Operating temperature	-40 °C...85 °C
Humidity	5...85 % rel. humidity, no condensation		

Rated data UL

Certificate No. (cURus)	E351070
-------------------------	---------

Control side

Rated control voltage	60 V DC	Rated current DC	3 mA
Power rating	180 mW	Coil resistance	20570 $\Omega \pm 10\%$
Coil tolerance	10 %	Status indicator	No

Load side

Rated switching voltage	250 V AC	Max. switching frequency at rated load	0.1 Hz
Max. switching voltage, AC	250 V	Max. switching voltage, DC	250 V
AC switching capacity (resistive), max.	1500 VA	DC switching capacity (resistive), max.	144 W @ 24 V
Switch-on delay	<8 ms	Switch-off delay	<4 ms
Contact type	1 CO contact (AgNi gold-plated)	Mechanical service life	5 x 10 ⁶ switching cycles
Min. switching power	1 mA @ 1 V		

General data

Test button available	No	Mechanical switch position indicator	No
Colour	white	UL 94 flammability rating	V-0

Insulation coordination

Clearance and creepage distances for control side - load side	≥ 6 mm	Dielectric strength for control side - load side	4 kV _{eff} / 1 Min.
Dielectric strength of open contact	1 kV _{eff} / 1 min	Protection degree	IP67

Further details of approvals / standards

Certificate No. (VDE)	40029391	Certificate No. (cURus)	E351070
-----------------------	----------	-------------------------	---------

Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Classifications

ETIM 6.0	EC001437	ETIM 7.0	EC001437
ETIM 8.0	EC001437	ETIM 9.0	EC001437
ECLASS 9.0	27-37-16-01	ECLASS 9.1	27-37-16-01
ECLASS 10.0	27-37-16-01	ECLASS 11.0	27-37-16-01
ECLASS 12.0	27-37-16-01	ECLASS 13.0	27-37-16-01

Environmental Product Compliance

REACH SVHC

/

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cULus)	E351070

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com


Drawings

Wiring diagram

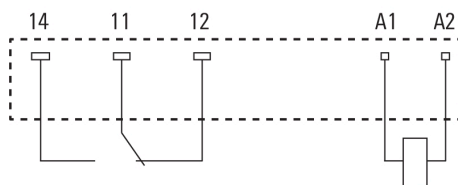


View of Pins from below

Graph

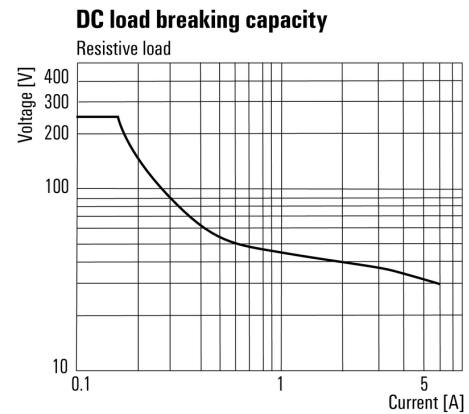


DC load limit curve

Graph

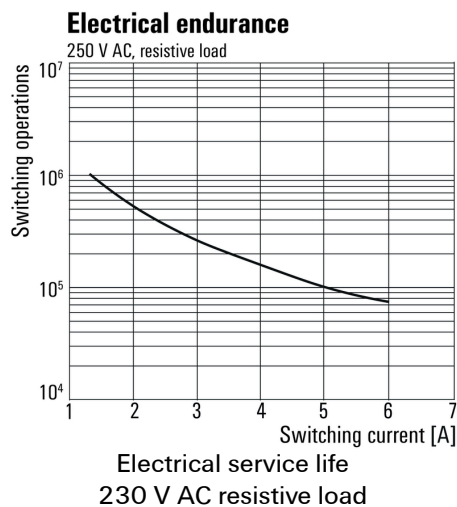

Dimensional drawing

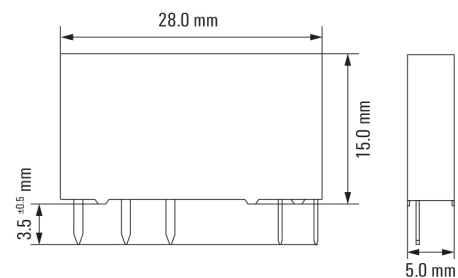

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Tension clamp connection



TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 230VAC RC 1CO EMPTY	Version
Order No.	1123440000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905171	control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
Qty.	10 pc(s).	
Type	TRZ 120VUC 1CO EMPTY	Version
Order No.	1123410000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905690	control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
Qty.	10 pc(s).	
Type	TRZ 120VAC RC 1CO EMPTY	Version
Order No.	1123430000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905188	control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
Qty.	10 pc(s).	
Type	TRZ 230VUC 1CO EMPTY	Version
Order No.	1123420000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905683	control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
Qty.	10 pc(s).	
Type	TRZ 60VUC 1CO EMPTY	Version
Order No.	1123400000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905546	control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
Qty.	10 pc(s).	

Screw connection



TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 230VUC 1CO EMPTY	Version
Order No.	1123300000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905515	control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, Screw connection
Qty.	10 pc(s).	

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	TRS 120VAC RC 1CO EMPTY	Version
Order No.	1123310000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905317	control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, Screw
Qty.	10 pc(s).	connection
Type	TRS 60VUC 1CO EMPTY	Version
Order No.	1123280000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905270	control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, Screw
Qty.	10 pc(s).	connection
Type	TRS 230VAC RC 1CO EMPTY	Version
Order No.	1123320000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905522	control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, Screw
Qty.	10 pc(s).	connection
Type	TRS 120VUC 1CO EMPTY	Version
Order No.	1123290000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905461	control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Screw
Qty.	10 pc(s).	connection

PUSH IN connection



TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 120VUC 1CO EMPTY	Version
Order No.	2618950000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118667585	control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 pc(s).	
Type	TRP 230VAC RC 1CO EMPTY	Version
Order No.	2618890000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669947	control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 pc(s).	
Type	TRP 120VAC RC 1CO EMPTY	Version
Order No.	2618880000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669954	control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 pc(s).	
Type	TRP 60VUC 1CO EMPTY	Version
Order No.	2618900000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669930	control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 pc(s).	
Type	TRP 230VUC 1CO EMPTY	Version
Order No.	2618960000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118667578	control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 pc(s).	

RSS112060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold


Germany

www.weidmueller.com

Drawings

Miscellaneous

Type code electromechanical relay (TERMSERIES)

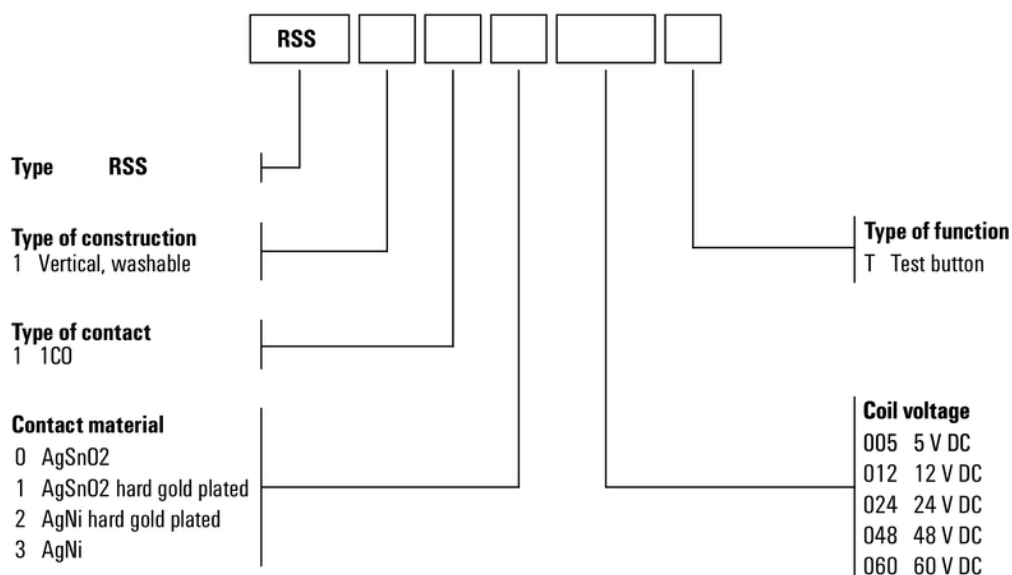

Type codes