

IE-P-IP67**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

SnapIn plug-in connectors according to IEC 61076-3-106
ver.6 in plastic, with RJ45 insert

General ordering data

Version	Connecting plug, Plug, IP67, Cat.6 _A / Class E _A (ISO/IEC 11801 2010), Variant 6 to IEC 61076-3-106
Order No.	8808380000
Type	IE-P-IP67
GTIN (EAN)	4032248505968
Qty.	1 pc(s).

IE-P-IP67

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	29 g
------------	------

Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

General data

Connection 1	RJ45	Connection 2	IDC
Description of article	Plug	Wiring	EIA/TIA T568 A
Colour	Light Grey	Housing main material	PA 66, UL 94: V-0
Category	Cat.6A / Class EA (ISO/IEC 11801 2010)	Contact surface	Gold over nickel
Type of mounting	Floor-mounted, for exposed connections, Wall mounting	Shielding	360°; shield contact
Protection degree	IP67	Plugging cycles	750

General standards

Certificate No. (DNV)	TAE00003EW	Connector standard	IEC 61076-3-106 Var. 6, IEC 60603-7-5
-----------------------	------------	--------------------	---------------------------------------

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ETIM 9.0	EC001121
ECLASS 9.0	27-44-03-90	ECLASS 9.1	27-44-03-90
ECLASS 10.0	27-44-03-90	ECLASS 11.0	27-44-03-90
ECLASS 12.0	27-44-03-90	ECLASS 13.0	27-44-03-90
ECLASS 14.0	27-44-03-90		

Environmental Product Compliance

REACH SVHC	/
RoHS Compliance Status	Compliant without exemption

Approvals

Approvals



ROHS	Conform
------	---------

IE-P-IP67

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Con-
formity

[GOST Approval](#)

Engineering Data

[CAD data – STEP](#)

User Documentation

[MAN IE GUIDE DE](#)

[MAN IE GUIDE EN](#)

Catalogues

[Catalogues in PDF-format](#)

Brochures

[FL FIELDWIRING EN](#)

[PI PROFINET CABLING EN](#)

[PI PROFINET CABLING EN](#)


IE-P-IP67

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

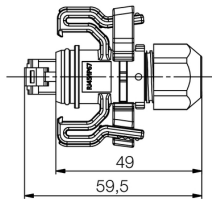

IE-P-IP67**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****... for modular plug-in connectors****Crimping tools for modular plug-in connector systems WE and DEC**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- Three functions in one tool

General ordering data

Type	TT 8 RS MP 8	Version
Order No.	9202800000	Pressing tools, Crimping tool for contacts
GTIN (EAN)	4032248512072	
Qty.	1 pc(s).	

RJ45 crimp

RJ45 crimp plug-in connector according to IEC 60603-7-51 for wire outer diameters up to 1.05 mm

General ordering data

Type	IE-PM-RJ45-TH	Version
Order No.	1963580000	RJ45 crimp plug, Plug without bending protection sleeve, Cat.6A /
GTIN (EAN)	4032248645688	Class EA (ISO/IEC 11801 2010)
Qty.	100 pc(s).	