

RIM-I 2 6/24VDC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Product image**

Similar to illustration

Pluggable protective modules for the RIDERSERIES RCI / RCM relay sockets, with optional protective functions.

- Optional with green or red LED
- With free-wheeling diode
- For DC supply voltage

General ordering data

| | |
|------------|--|
| Version | RIDERSERIES, LED module with freewheel diode, Rated control voltage: 6...24 V DC, Plug-in connection |
| Order No. | 8869590000 |
| Type | RIM-I 2 6/24VDC |
| GTIN (EAN) | 4032248614530 |
| Qty. | 10 pc(s). |

RIM-I 2 6/24VDC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

| | | | |
|------------|---------|-----------------|------------|
| Depth | 32.1 mm | Depth (inches) | 1.264 inch |
| Height | 10.5 mm | Height (inches) | 0.413 inch |
| Width | 11.4 mm | Width (inches) | 0.449 inch |
| Net weight | 1.9 g | | |

Temperatures

| | | | |
|---------------------|--|-----------------------|----------------|
| Storage temperature | -40 °C...70 °C | Operating temperature | -40 °C...70 °C |
| Humidity | 40 °C / 93 % rel. humidity, no condensation | | |

Rated data UL

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E223759 |
|-------------------------|---------|

Control side

| | | | |
|-----------------------|---------------------|------------------|---------|
| Rated control voltage | 6...24 V DC | Rated current DC | 1.5 mA |
| Power rating | 35 mW | Status indicator | red LED |
| Protective circuit | Free-wheeling diode | | |

General data

| | |
|--------|-------------|
| Colour | Transparent |
|--------|-------------|

Further details of approvals / standards

| | |
|-------------------------|---------|
| Certificate No. (cURus) | E223759 |
|-------------------------|---------|

Connection data

| | |
|------------------------|--------------------|
| Wire connection method | Plug-in connection |
|------------------------|--------------------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002586 | ETIM 7.0 | EC002586 |
| ETIM 8.0 | EC002586 | ETIM 9.0 | EC002586 |
| ECLASS 9.1 | 27-37-10-10 | ECLASS 10.0 | 27-37-10-10 |
| ECLASS 11.0 | 27-37-16-92 | ECLASS 12.0 | 27-37-16-92 |
| ECLASS 13.0 | 27-37-16-92 | ECLASS 14.0 | 27-37-16-92 |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| REACH SVHC | / |
| RoHS Compliance Status | Compliant without exemption |

RIM-I 2 6/24VDC

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search UL Website

Certificate No. (cURus) E223759

Downloads

Engineering Data [CAD data – STEP](#)Catalogues [Catalogues in PDF-format](#)

Brochures


RIM-I 2 6/24VDC

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Wiring diagram

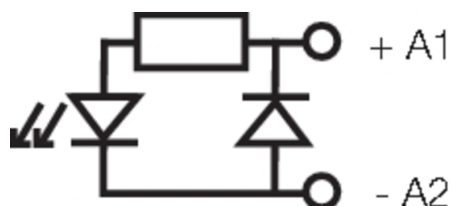

Dimensional drawing

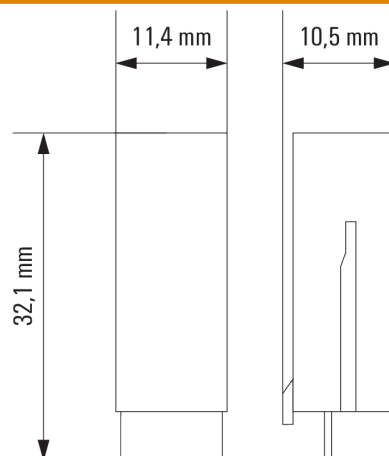

RIM-I 2 6/24VDC**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Miscellaneous**

| Order No. | Type | Type code printed on part |
|------------|-----------------------|------------------------------|
| 8869770000 | RIM-I 3 6/60VAC | EM 02 |
| 8869790000 | RIM-I 3 110/230VAC | EM 03 |
| 8869710000 | RIM-I 4 24 UC VAR | EM 04 |
| 8869750000 | RIM-I 4 230 VUC CAR | EM 05 |
| 8869650000 | RIM-I 3 110/230VUC | EM 06 |
| 8869630000 | RIM-I 3 6/24VUC | EM 07 |
| 8869580000 | RIM-I 1 6/230V | EM 09 |
| 8869660000 | RIM-I 3 110/230VUC GN | EM 10 |
| 8869640000 | RIM-I 3 6/24VUC GN | EM 11 |
| 8869600000 | RIM-I 2 6/24VDC GN | EM 12 |
| 8869730000 | RIM-I 4 110 VUC VAR | EM 13 |
| 8869610000 | RIM-I 3 24/60VUC | EM 14 |
| 8869670000 | RIM-I 2 24/60VDC | EM 16 |
| 8869590000 | RIM-I 2 6/24VDC | EM 18 |
| 8869680000 | RIM-I 2 24/60VDC GN | EM 25 |
| 8869690000 | RIM-I 2 110/230VDC | EM 27 |
| 8869700000 | RIM-I 2 110/230VDC GN | EM 28 |
| 8870830000 | RIM-I R 110/230V | EM 29 |
| 8869620000 | RIM-I 3 24/60VUC GN | EM 30 |
| 1172210000 | RIM-I 3 230VAC RC | EM 31 |