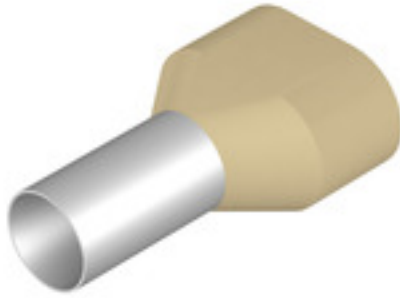


**H10,0/24S ZH EB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, Ivory
Order No.	<a href="#">9018860000</a>
Type	H10,0/24S ZH EB
GTIN (EAN)	4032248105816
Qty.	100 pc(s).
Packaging	loose

**H10,0/24S ZH EB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Net weight	0.84 g
------------	--------

**Technical data**

Description of article	Twin wire end ferrule, ivory	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

**Wire-end ferrules**

Collar height (A)	13.4 mm	Collar width (B)	7.6 mm
Colour code	Weidmueller	Conductor cross-section	10 mm <sup>2</sup>
Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	12 mm
L1 in mm	24 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm	Stripping length	17 mm
Wire connection cross section AWG, max.	AWG 8		

**Classifications**

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">Technical information - EN</a> <a href="#">Technical information - DE</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

**H10,0/24S ZH EB****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Drawings****Drawing**