

## H70,0/37 GE


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

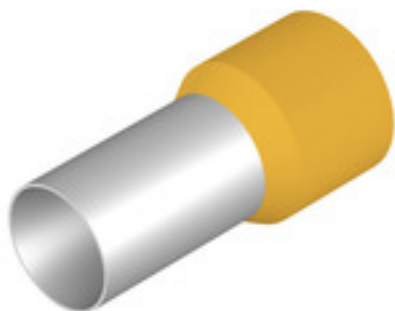

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

### General ordering data

Version	Wire-end ferrule, Standard, 26 mm, 21 mm, yellow
Order No.	<a href="#">9028200000</a>
Type	H70,0/37 GE
GTIN (EAN)	4008190891572
Qty.	25 pc(s).
Packaging	loose

**H70,0/37 GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Net weight	3.9 g
------------	-------

**Technical data**

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

**Wire-end ferrules**

Collar diameter (D2)	16 mm	Colour code	Weidmueller
Conductor cross-section	70 mm <sup>2</sup>	Contact surface diameter (D1)	12.7 mm
Contact surface length (L2)	21 mm	L1 in mm	37 mm
Metal sleeve thickness (S1)	0.35 mm	Plastic collar thickness (S2)	0.6 mm
Stripping length	26 mm	Wire connection cross section AWG, max.	AWG 2/0

**Classifications**

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

**Environmental Product Compliance**

REACH SVHC	/
------------	---

**Approvals**

ROHS	Conform
------	---------

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">Zuken E3.S</a>
User Documentation	<a href="#">Technical information - EN</a> <a href="#">Technical information - DE</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## H70,0/37 GE

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Drawings

## Drawing

