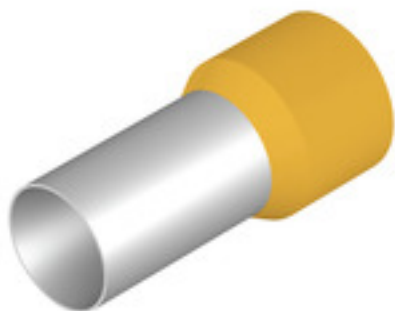


H150,0/54 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 38 mm, 32 mm, yellow
Order No.	9028230000
Type	H150,0/54 GE
GTIN (EAN)	4008190891602
Qty.	25 pc(s).
Packaging	loose

H150,0/54 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Net weight	10.8 g
------------	--------

Technical data

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	23.5 mm	Colour code	Weidmueller
Conductor cross-section	150 mm ²	Contact surface diameter (D1)	18.5 mm
Contact surface length (L2)	32 mm	L1 in mm	54 mm
Metal sleeve thickness (S1)	0.5 mm	Plastic collar thickness (S2)	0.75 mm
Stripping length	38 mm	Wire connection cross section AWG, max.	AWG 300 MCM

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

Environmental Product Compliance

REACH SVHC	/
------------	---

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

H150,0/54 GE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Drawings****Drawing**