

**TBF 60/37/21 TRSP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Similar to illustration**

The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.

**Features:**

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

**General ordering data**

Version	TBF (polyester empty enclosure), Empty enclosure, Height: 603 mm, Width: 372 mm, Depth: 210 mm, Material: Glass fibre-reinforced polyester, untreated, Light Grey, Transparent
Order No.	<a href="#">9502860000</a>
Type	TBF 60/37/21 TRSP
GTIN (EAN)	4008190994907
Qty.	1 pc(s).

## TBF 60/37/21 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	210 mm	Depth (inches)	8.268 inch
Height	603 mm	Height (inches)	23.74 inch
Width	372 mm	Width (inches)	14.646 inch
Net weight	4,638 g		

## Temperatures

Operating temperature	-50 °C...130 °C
-----------------------	-----------------

## Cable glands, right

M12	88	M16	48
M20	40	M25	20
M32	8	M40	6
M50	6	M63	4

## Cable glands, top/bottom

M12	52	M16	30
M20	26	M25	12
M32	5	M40	4
M50	4	M63	3

## Certificate numbers enclosure

Declaration of Conformity No. (DoC LVD)	DoC DE PS2422 230801 001ISS00
---	-------------------------------

## General information

Access opening: height	578 mm	Access opening: width	347 mm
Areas of use	Building systems and technology, Transportation, Packaging industry, Machine construction	Enclosure attachment	6.5 mm hole in enclosure base
Flange plate	No	Impact resistance	IK08 in accordance with IEC 62208, IK10 in accordance with IEC 62262
Installation advice	Screw mounting	Integral fixing	4 or 6 stud bolts M6 inner (female) thread
Lid	Yes	Lid attachment	Crosshead nylon screws
Material	Glass fibre-reinforced polyester	Number of lid screws	6
Operating temperature, max.	130 °C	Operating temperature, min.	-50 °C
Protection degree	IP66	Seal material	Polyurethane
Standards	IEC 60529, EN 60529, EN 62208, EN/IEC 61439-2	Surface finish	untreated
Torque for lid screws	1.5 Nm	Toxicity	Free from halogens
UL 94 flammability rating	V-2		

## horizontal assembly

WDU 10 / ZDU 10	2x51	WDU 16 / ZDU 16	2x37
WDU 2,5 / ZDU 2,5 / IDU 2,5	2x101	WDU 35 / ZDU 35	2x32
WDU 4 / ZDU 4	2x85	WDU 6 / ZDU 6	2x64

Creation date May 23, 2024 6:57:03 AM CEST

**TBF 60/37/21 TRSP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****vertical assembly**

WDU 10 / ZDU 10	5x29	WDU 16 / ZDU 16	5x21
WDU 2,5 / ZDU 2,5 / IDU 2,5	5x57	WDU 35 / ZDU 35	5x18
WDU 4 / ZDU 4	5x48	WDU 6 / ZDU 6	5x36

**Classifications**

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ETIM 9.0	EC000261
ECLASS 9.0	27-18-01-01	ECLASS 9.1	27-18-92-90
ECLASS 10.0	27-18-01-01	ECLASS 11.0	27-18-01-01
ECLASS 12.0	27-18-01-01	ECLASS 13.0	27-18-01-01

**Approvals**

ROHS	Conform
------	---------

**Downloads**


Approval/Certificate/Document of Conformity	<a href="#">EU Declaration of Conformity - TBF Empty Enclosures - DoC DE PS2420 220224 002ISS00</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## TBF 60/37/21 TRSP

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

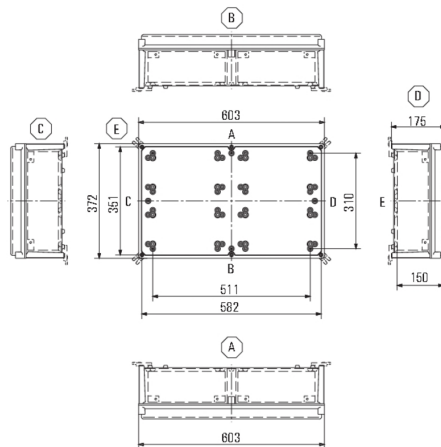

## TBF 60/37/21 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## External fixing lugs



The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.


## Features:

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

## General ordering data

Type	MF TBF	Version
Order No.	<a href="#">0360800000</a>	TBF (polyester empty enclosure), Mounting foot, Fixing lugs, Height:
GTIN (EAN)	4008190108595	72.5 mm, Width: 24 mm, Depth: 12 mm, Material: Polyamide, Deep
Qty.	1 pc(s).	black

## Mounting plate

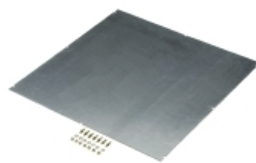

The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.

## Features:

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

## General ordering data

Type	MP TBF 60/37	Version
Order No.	<a href="#">9502910000</a>	TBF (polyester empty enclosure), Mounting plate, Mounting plate,
GTIN (EAN)	4008190994914	Height: 550 mm, Width: 319 mm, Depth: 2 mm, Material: Sheet steel,
Qty.	1 pc(s).	galvanized, galvanized, silver

## TBF 60/37/21 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Ventilation plugs - DAE



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

## General ordering data

Type	DAE M12 SS	Version
Order No.	<a href="#">1868550000</a>	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440405	mm, IP66, IP68, IP69K, Stainless steel 1.4305 (303)
Qty.	10 pc(s).	
Type	DAE M12 PA LONG	Version
Order No.	<a href="#">1868570000</a>	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440429	mm, IP66, IP68, IP69K, Polyamide 6
Qty.	10 pc(s).	

## Earthing stud

## Accessories



## General ordering data

Type	PEBZ M10 S4 SET	Version
Order No.	<a href="#">1283440000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073362	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M10 BR SET	Version
Order No.	<a href="#">1277220000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067019	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M6 S4 SET	Version
Order No.	<a href="#">1283430000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073607	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M6 BR SET	Version
Order No.	<a href="#">1277250000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067149	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Brass