

HDC MPN 2

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

Általános rendelési adatok

Változat	Pneumatikus modul
Rendelési szám	2637320000
Típus	HDC MPN 2
GTIN (EAN)	4050118767520
Qty.	1 Stück

HDC MPN 2

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Műszaki adatok

Méretetek és tömegek

Nettó tömeg	0,55 g
-------------	--------

Hőmérsékletek

Hőmérsékleti határérték	-40 °C ... 80 °C
-------------------------	------------------

Pneumatikus modul

Modul üzemi nyomása	8 bar	Tömlő belső átmérője, min.	6 mm
Tömlő belső átmérője, max.	6 mm		

Verzió

Csatlakozás típusa	Csőcsatlakozás (pneumatika)
--------------------	-----------------------------

Általános adatok

Anyag	polikarbonát, üvegszál-erősítésű	Dugaszhelyek szükséges száma	1
Dugaszolási ciklusok	≥ 500	Pólusszám	2
Sorozat	ModuPlug	Típus	Dugó, Hüvely
UL 94 éghetőségi osztály	V-0		

Besorolások

ETIM 6.0	EC000438	ETIM 7.0	EC000438
ETIM 8.0	EC000438	ETIM 9.0	EC000438
ECLASS 9.0	27-44-02-20	ECLASS 9,1	27-44-02-20
ECLASS 10.0	27-44-02-20	ECLASS 11.0	27-44-02-20
ECLASS 12.0	27-44-02-20	ECLASS 13.0	27-44-02-20

Termékek környezetvédelmi megfelelése

REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	1609748e-c278-4c9b-b3d1-e6215d2988cd

Letöltések




Approval/Certificate/Document of Conformity	Manufacturer's declaration
Engineering Data	CAD data – STEP
Katalógusok	Catalogues in PDF-format

HDC MPN 2

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Rajzok

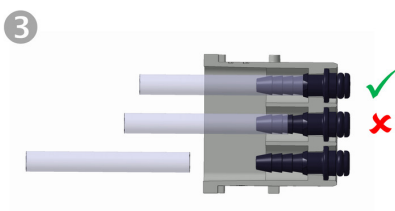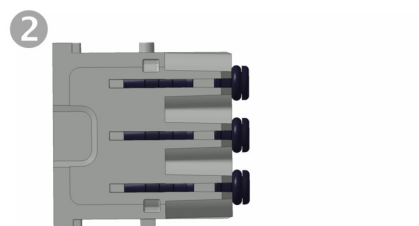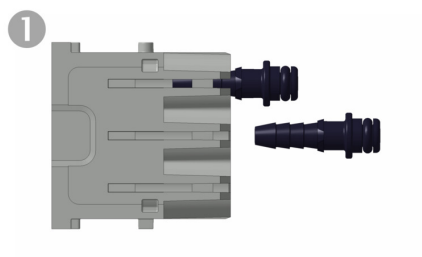

HDC MPN 2

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Tartozékok

Pneumatikus csatlakozók

**Make your connections fit for the future With the advanced solutions from RockStar® ModuPlug**

Industrial applications are becoming increasingly complex. The demands being made of the connectivity used are growing at the same time. Functionality in the smallest of installation spaces, safe installation and a fast retrofitting process are just some of the product properties being called for. Not only does our RockStar® ModuPlug modular plug-in connector system meet current market requirements; it has been specially designed with the future in mind too. Using the individual modules, you combine all the necessary functions for power, signal and data transmission in a single interface. Thanks to the new variety of module sizes, you can fit more applications than ever before in one plug-in connector. The modules reduce the amount of space required and cut costs when compared with fixed-pole inserts and other modular plug-in connector systems. The sophisticated frames and modules can be installed with extreme ease and integrated into HDC enclosures with the IP65 and IP68 protection classes. You can even use the RockStar® ModuPlug to supplement existing applications without any need to make system adjustments. As an experienced Industrial Connectivity partner, Weidmüller offers ultra-modern connectivity with maximum reliability. So you can create customised solutions for future-proof connections with RockStar® too.

Általános rendelési adatok

Típus	HDC MPN 6.0 SOF	Változat
Rendelési szám	637400000	Pneumatikus csatlakozók, Érintkezés a szeleppel: Igen
GTIN (EAN)	4050118654547	
Qty.	10 Stück	
Típus	HDC MPN 6.0 F	Változat
Rendelési szám	637390000	Pneumatikus csatlakozók, Érintkezés a szeleppel: Nem
GTIN (EAN)	4050118654530	
Qty.	10 Stück	
Típus	HDC MPN 6.0 M	Változat
Rendelési szám	637350000	Pneumatikus csatlakozók, Érintkezés a szeleppel: Nem
GTIN (EAN)	4050118654615	
Qty.	10 Stück	