

**TBF 19/15/14 TRSP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Similar to illustration**

The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.

**Features:**

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

**General ordering data**

Version	TBF (polyester empty enclosure), Empty enclosure, Height: 186 mm, Width: 151 mm, Depth: 140 mm, Material: Glass fibre-reinforced polyester, Miscellaneous, Light Grey, Transparent
Order No.	<a href="#">0500500000</a>
Type	TBF 19/15/14 TRSP
GTIN (EAN)	4032248043828
Qty.	1 pc(s).
Delivery status	<b>This article will no longer be available in the future.</b>
Available until	2022-11-08

## TBF 19/15/14 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	140 mm	Depth (inches)	5.512 inch
Height	186 mm	Height (inches)	7.323 inch
Width	151 mm	Width (inches)	5.945 inch
Net weight	810 g		

## Temperatures

Operating temperature	-50 °C...130 °C
-----------------------	-----------------

## Cable glands, right

M12	11	M16	6
M20	2	M25	2
M32	1	M40	1

## Cable glands, top/bottom

M12	11	M16	6
M20	2	M25	2
M32	1	M40	1

## Certificate numbers enclosure

Declaration of Conformity No. (DoC LVD)	DoC DE PS2422 230801 001ISS00
---	----------------------------------

## General information

Access opening: height	162 mm	Access opening: width	127 mm
Areas of use	Building systems and technology, Transportation, Packaging industry, Machine construction	Enclosure attachment	6.5 mm hole in enclosure base
Flange plate	No	Impact resistance	IK08 in accordance with IEC 62208, IK10 in accordance with IEC 62262
Integral fixing	4 or 6 stud bolts M6 inner (female) thread	Lid	Yes
Lid attachment	Crosshead nylon screws	Material	Glass fibre-reinforced polyester
Number of lid screws	4	Operating temperature, max.	130 °C
Operating temperature, min.	-50 °C	Protection degree	IP66
Seal material	Polyurethane	Standards	IEC 60529, EN 60529, EN 62208, EN/IEC 61439-2
Surface finish	Miscellaneous	Torque for lid screws	1.5 Nm
Toxicity	Free from halogens	UL 94 flammability rating	V-2

## horizontal assembly

WDU 10 / ZDU 10	1x9	WDU 16 / ZDU 16	1x6
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x18	WDU 35 / ZDU 35	1x5
WDU 4 / ZDU 4	1x15	WDU 6 / ZDU 6	1x11

**TBF 19/15/14 TRSP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****vertical assembly**

WDU 10 / ZDU 10	1x6	WDU 16 / ZDU 16	1x4
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x11	WDU 35 / ZDU 35	1x3
WDU 4 / ZDU 4	1x9	WDU 6 / ZDU 6	1x7

**Classifications**

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ETIM 9.0	EC000261
ECLASS 9.0	27-18-01-01	ECLASS 9.1	27-18-92-90
ECLASS 10.0	27-18-01-01	ECLASS 11.0	27-18-01-01
ECLASS 12.0	27-18-01-01	ECLASS 13.0	27-18-01-01

**Approvals**

ROHS	Conform
------	---------

**Downloads**


Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

## TBF 19/15/14 TRSP

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

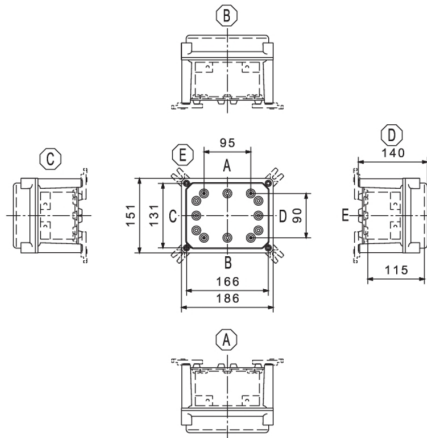

## TBF 19/15/14 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## External fixing lugs



The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.


## Features:

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

## General ordering data

Type	MF TBF	Version
Order No.	<a href="#">0360800000</a>	TBF (polyester empty enclosure), Mounting foot, Fixing lugs, Height:
GTIN (EAN)	4008190108595	72.5 mm, Width: 24 mm, Depth: 12 mm, Material: Polyamide, Deep
Qty.	1 pc(s).	black

## Mounting plate

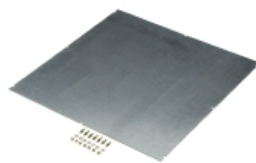

The enclosures of the TBF series are made of extremely tough glass fibre-reinforced polyester. These enclosures are ideal for applications that call for low weight coupled with high shock resistance. The weather-resistant TBF enclosures are designed for a wide range of applications. Together with their comprehensive range of accessories, they provide universal solutions for accommodating built-in items such as regulators, measuring instruments, valves and other equipment.

## Features:

- 9 sizes in 2 versions, with grey and transparent lids
- Cover with nylon screws
- Fixing holes outside the sealed area
- Thread for fitting to terminal rails and mounting plates
- Comprehensive accessories
- Weidmüller can manufacture and supply this enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

## General ordering data

Type	MP TBF 19/15	Version
Order No.	<a href="#">9502720000</a>	TBF (polyester empty enclosure), Mounting plate, Mounting plate,
GTIN (EAN)	4032248002139	Height: 134 mm, Width: 99 mm, Depth: 2 mm, Material: Sheet steel,
Qty.	1 pc(s).	galvanized, galvanized, silver

## TBF 19/15/14 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## Earthing stud

## Accessories



## General ordering data

Type	PEBZ M6 BR SET	Version
Order No.	<a href="#">1277250000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067149	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M10 BR SET	Version
Order No.	<a href="#">1277220000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067019	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Brass
Type	PEBZ M6 S4 SET	Version
Order No.	<a href="#">1283430000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073607	Miscellaneous, Height: 12.3 mm, Width: 12.3 mm, Depth: 42 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)
Type	PEBZ M10 S4 SET	Version
Order No.	<a href="#">1283440000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073362	Miscellaneous, Height: 21 mm, Width: 21 mm, Depth: 48.7 mm,
Qty.	1 pc(s).	Material: Stainless steel 1.4404 (316L)

## Ventilation plugs - DAE



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

## General ordering data

Type	DAE M12 PA LONG	Version
Order No.	<a href="#">1868570000</a>	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440429	mm, IP66, IP68, IP69K, Polyamide 6
Qty.	10 pc(s).	
Type	DAE M12 SS	Version
Order No.	<a href="#">1868550000</a>	DAE (ventilation element), Compensating element, straight, M 12, 10
GTIN (EAN)	4032248440405	mm, IP66, IP68, IP69K, Stainless steel 1.4305 (303)
Qty.	10 pc(s).	