

IE-BH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connectors according to IEC
61076-3-106 ver.1 (Ethernet/IP), plastic, empty housing

General ordering data

Version	Empty enclosure, Flange-mounted housing, IP67
Order No.	1016960000
Type	IE-BH-V01P
GTIN (EAN)	4032248738939
Qty.	10 pc(s).

IE-BH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Technical data****Dimensions and weights**

Depth	22.8 mm	Depth (inches)	0.898 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	2 g		

Temperatures

Operating temperature	-40 °C...70
-----------------------	-------------

General data

Colour		Configuration	Plug housing with labelling/marketing holder: 9*11 mm; suitable for holding RJ45 and fibre-optic inserts
	black		
Housing main material	PA UL 94 V0	Plugging cycles	750
Protection degree	IP67		

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ETIM 9.0	EC001031
ECLASS 9.0	27-18-27-02	ECLASS 9.1	27-18-27-02
ECLASS 10.0	27-18-27-02	ECLASS 11.0	27-18-27-02
ECLASS 12.0	27-18-27-02	ECLASS 13.0	27-19-01-04

Environmental Product Compliance

REACH SVHC	6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	11b17e97-f803-4c09-9278-b20f22f15f81

Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	DUXR.E316369
Engineering Data	CAD data – STEP
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-BH-V01P

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Installation cut-out

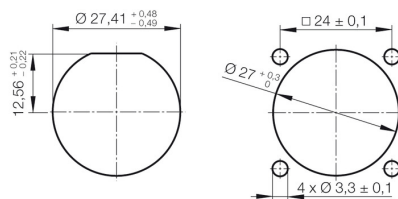

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

IE-BH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****Dust caps**

For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version
Order No.	1965700000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 pc(s).	

USBUSB inserts for FrontCom[®]**General ordering data**

Type	IE-BI-USB-A	Version
Order No.	1019570000	USB insert, Flange insert, type A
GTIN (EAN)	4032248731602	
Qty.	10 pc(s).	

IE-BH-V01P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****LWL-SC**

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-BI-SCRJ2SC-SM-C	Version
Order No.	1962870000	SC insert, Bulkhead insert SCRJ to 2 SC, singlemode
GTIN (EAN)	4032248645060	
Qty.	10 pc(s).	
Type	IE-BI-SCRJ2SC-MM-C	Version
Order No.	1964430000	SC insert, Bulkhead insert SCRJ to 2 SC, multimode
GTIN (EAN)	4032248649044	
Qty.	10 pc(s).	

LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Type	IE-BI-LCD-SM-C	Version
Order No.	1962880000	LC insert, Bulkhead insert LC duplex, singlemode
GTIN (EAN)	4032248645077	
Qty.	10 pc(s).	
Type	IE-BI-LCD-MM-C	Version
Order No.	1964420000	LC insert, Bulkhead insert LC duplex, multimode
GTIN (EAN)	4032248649037	
Qty.	10 pc(s).	

IE-BH-V01P

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

RJ45

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...



General ordering data

Type	IE-BI-RJ45-C	Version
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 pc(s).	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 pc(s).	

Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14



General ordering data

Type	IE-BIC-HYB-P-0,5-300	Version
Order No.	1096150000	Crimp contact, for flange insert, Hybrid
GTIN (EAN)	4032248869114	
Qty.	300 pc(s).	
Type	IE-BI-HYB-10P	Version
Order No.	1069010000	Flange insert, for flange insert, Hybrid
GTIN (EAN)	4032248823970	
Qty.	10 pc(s).	