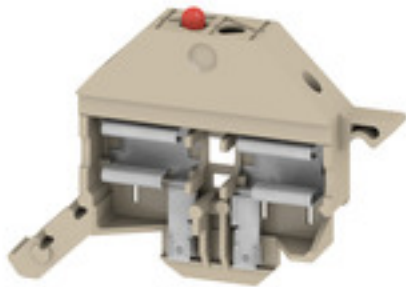


**TNHE WSI6 60-150V DC/AC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

**General ordering data**

Version	W-Series, Isolating lever
Order No.	<a href="#">1035500000</a>
Type	TNHE WSI6 60-150V DC/AC
GTIN (EAN)	4008190205539
Qty.	50 pc(s).

**TNHE WSI6 60-150V DC/AC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Dimensions and weights**

Depth	28.8 mm	Depth (inches)	1.134 inch
Height	50.15 mm	Height (inches)	1.974 inch
Width	6.95 mm	Width (inches)	0.274 inch
Net weight	5.66 g		

**Temperatures**

Storage temperature	-25 °C...55 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	120 °C		

**Material data**

Material	Wemid	Colour	dark beige
UL 94 flammability rating	V-0		

**Additional technical data**

Explosion-tested version	No	Installation advice	Direct mounting
Type of fixing	Snap-on		

**Dimensions**

Pitch in mm (P)	7.8 mm
-----------------	--------

**General**

Installation advice	Direct mounting
---------------------	-----------------

**Rating data**

Rated current	0 A
---------------	-----

**Classifications**

ETIM 6.0	EC002848	ETIM 7.0	EC002848
ETIM 8.0	EC002848	ETIM 9.0	EC002848
ECLASS 9.0	27-14-11-92	ECLASS 9.1	27-14-11-92
ECLASS 10.0	27-14-11-92	ECLASS 11.0	27-14-11-92
ECLASS 12.0	27-14-11-92	ECLASS 13.0	27-25-03-90

**Approvals**

Approvals



ROHS	Conform
------	---------

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
------------	--

### TNHE WSI6 60-150V DC/AC

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Drawings

